



aerospace
climate control
electromechanical
filtration
fluid & gas handling
hydraulics
pneumatics
process control
sealing & shielding



Parker Village Marine Offshore Desalination Systems



ENGINEERING YOUR SUCCESS.




Parker Village Marine PW-3000
(See bulletin no. 7831)

The Pure Water (PW) Series is designed to provide installation flexibility, superior performance, and extended service life in the most rugged conditions. PW units are typically installed in 24/7, continuous-duty applications. Each features a 3 or 5 plunger titanium pump for low vibration and low noise with unsurpassed corrosion resistance.



Parker Village Marine
PW-8000 XP Explosion Proof
(See bulletin no. 7857)

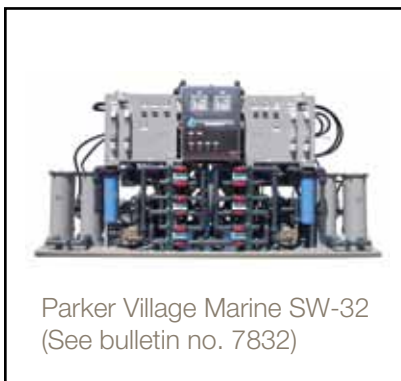

Parker Village Marine SW-32
(See bulletin no. 7832)

Parker Village Marine (VMT) offers a wide range of watermaker systems for offshore platforms and vessels. The PW and SW series offer standard catalog units providing quick delivery for many applications. The CC series provides unique engineered solutions to suit customer specifications. VMT is able to collaborate with customer technical staff to meet specific requirements.

Pure Water Series

3,000-20,000 GPD (11,000-75,500 LPD)
For Offshore Support Vessels, ROV Support Vessels, Cable Laying Ships, Pipe Laying Barges, Anchor Handling Tugs, etc.

Model	Capacity GPH-m ³ /D	Power HP	Dimensions W x D x H inch (cm)	Weight lbs./kg
PW3000	125 - 11	12	84(213)x34(86)x35(89)	800/364
PW4000	167 - 15	12	84(213)x34(86)x35(89)	900/409
PW5000	208 - 20	17	84(213)x34(86)x35(89)	1000/455
PW6000	250 - 25	17	84(213)x44(112)x35(89)	1050/477
PW7000	292 - 27	17	84(213)x48(122)x35(89)	1500/682
PW8000	333 - 30	22	84(213)x48(122)x35(89)	1600/727
PW10000	417 - 40	22	84(213)x48(122)x35(89)	1800/818
PW12000	500 - 45	27	88(224)x52(132)x35(89)	1900/864
PW16000	667 - 61	27	88(224)x52(132)x43(109)	2200/1000
PW20000	833 - 75	32	88(224)x52(132)x43(109)	2250/1022

Sea Water Series

24,000-40,000 GPD (91,000-150,000 LPD)
For Offshore Drilling Rigs, Construction Barges and FPSO's.

The Sea Water (SW) Series reverse osmosis desalination systems are designed to

provide potable water in demanding environments. These models comprise

(Continued on next page)

a single skid with two complete, independent RO systems. The two trains can run together or can be operated on a duty/stand by basis. Top quality components, manufactured by Parker Village Marine, provide maximum corrosion resistance. Straight-forward, easy to understand controls, result in reliable operation.



SW Series (back side view)



SW Series (right side view)

Model	Capacity		Power at 440/3/60	Dimensions inch/cm	Weight lb/kg
	GPD	m ³ /day			
SW 24	24000	91	60 Amps	142/361 long	6950/3160
SW 32	32000	120	60 Amps	72/183 deep	7300/3320
SW 40	40000	151	70 Amps	78/198 high	7500/3410



Parker Village Marine CC-10000 XP

The CC Series provides custom engineered solutions to meet customer specifications. Each one is configured with all accessories in a single box frame. The core of the system uses the proven AquaPro[®] titanium pressure pumps and membranes.



CC Series

2,000-26,000 GPD (7,500-100,000 LPD)
For Offshore FPSO, FSO, MODU and Drillships



Parker Village Marine
CC-2000 XP

Features can be selected from the following:

- Media filter pretreatment
- Carbon filter pretreatment
- De-chlorination pretreatment
- 2nd pass system for turbine/boiler water requirements
- Explosion proof ratings:
 - NEC class 1, division 1
 - NEC class 1, division 2
 - IEC 60079 zone 2, group IIA
- Remineralizer posttreatment for pH neutralization
- Ultraviolet light germicidal systems
- Chlorination post treatment
- Status and alarm signal for remote monitoring
- Full Supplier Document Requirement List vendor data book

Worldwide Filtration Manufacturing Locations

North America

**Compressed Air Treatment
Filtration & Separation/Balston**
Haverhill, MA
978 858 0505
www.parker.com/balston

**Finite Airtek Filtration
Airtek/domnick hunter/Zander**
Lancaster, NY
716 686 6400
www.parker.com/faf

Finite Airtek Filtration/Finite
Oxford, MI
248 628 6400
www.parker.com/finitefilter

**Engine Filtration &
Water Purification
Racor**
Modesto, CA
209 521 7860
www.parker.com/racor

Holly Springs, MS
662 252 2656
www.parker.com/racor

Beaufort, SC
843 846 3200
www.parker.com/racor

Racor – Village Marine
Carson, CA
310 608 5600
www.parker.com/watermakers

Parker Sea Recovery
Carson, CA
310 637 3400
www.searecovery.com

**Hydraulic Filtration
Hydraulic Filter**
Metamora, OH
419 644 4311
www.parker.com/hydraulicfilter

Laval, QC Canada
450 629 9594
www.parkerfarr.com

**Process Filtration
domnick hunter Process Filtration**
Oxnard, CA
805 604 3400
www.parker.com/processfiltration

Madison, WI
608 824 0500
www.scilog.com

Phoenixville, PA
610 933 1600
www.parker.com/processfiltration

**Aerospace Filtration
Velcon Filtration**
Colorado Springs, CO
719 531 5855
www.velcon.com

Europe

**Compressed Air Treatment
domnick hunter Filtration & Separation**
Gateshead, England
+44 (0) 191 402 9000
www.parker.com/dhfn

Parker Gas Separations
Etten-Leur, Netherlands
+31 76 508 5300
www.parker.com/dhfn

Hiross Zander
Padova Business Unit
Padova, Italy
+39 049 9712 111
www.parker.com/hzd

Hiross Zander
Essen Business Unit
Essen, Germany
+49 2054 9340
www.parker.com/hzd

**Engine Filtration &
Water Purification
Racor**
Dewsbury, England
+44 (0) 1924 487 000
www.parker.com/rfde

Racor Research & Development
Stuttgart, Germany
+49 (0)711 7071 290-10
www.parker.com/rfde

**Hydraulic Filtration
Hydraulic Filter**
Arnhem, Holland
+31 26 3760376
www.parker.com/hfde

Ujala Operation
Ujala, Finland
+358 20 753 2500
www.parker.com/hfde

Condition Monitoring Centre
Norfolk, England
+44 (0) 1842 763 299
www.parker.com/hfde

Parker Kittiwake
West Sussex, England
+44 (0) 1903 731 470
www.kittiwake.com

Parker Procal
Peterborough, England
+44 (0) 1733 232 495
www.kittiwake.com

**Process Filtration
domnick hunter Process Filtration**
Birtley, England
+44 (0) 191 410 5121
www.parker.com/processfiltration

Parker Twin Filter BV
Zaandam, Netherlands
+31(0)75 655 50 00
www.twfilter.com

Asia Pacific

Australia
Castle Hill, Australia
+61 2 9634 7777
www.parker.com/australia

China
Shanghai, China
+86 21 5031 2525
www.parker.com/china

India
Navi Mumbai, India
+91 22 651 370 8185
www.parker.com/india

Parker Fowler
Bangalore, India
+91 80 2783 6794
www.johnfowlerindia.com

Japan
Tokyo, Japan
+81 45 870 1522
www.parker.com/japan

Parker Techno
Osaka, Japan
+81 66 340 1600
www.techno.taiyo-ltd.co.jp

Korea
Hwaseon-City
+82 31 359 0852
www.parker.com/korea

Singapore
Jurong Town, Singapore
+65 6887 6300
www.parker.com/singapore

Thailand
Bangkok, Thailand
+66 2186 7000
www.parker.com/thailand

**Latin America
Parker Comercio Ltda.
Filtration Division**
Sao Paulo, Brazil
+55 12 4009 3500
www.parker.com/br

Pan American Division
Miami, FL
305 470 8800
www.parker.com/panam

Africa

Aeroporto Kempton Park, South Africa
+27 11 9610700
www.parker.com/africa

