



LLD Series



BI-FLOW FILTER DRIERS - GOLD LABEL		
Model	Connections	R22 / 410A Tons
BF082S	1/4" ODF	1 to 3-1/2
BF083	3/8" SAE Male	1 to 3-1/2
BF083S	3/8" ODF	1 to 3-1/2
BF084	1/2" SAE Male	1 to 3-1/2
BF084S	1/2" ODF	1 to 3-1/2
BF162S	1/4" ODF	1 to 8
BF163	3/8" SAE Male	1 to 8
BF163S	3/8" ODF	1 to 8
BF163S-XF	3/8" ODF	1 to 8
BF083S (Copper)	3/8" ODF	1 to 3-1/2
BF164	1/2" SAE Male	1 to 8
BF164S	1/2" ODF	1 to 8
BF165S	5/8" ODF	1 to 8



LIQUID LINE FILTER DRIERS - R410A *		
Model	Connections	R22 / 410A Tons
163S-XF	3/8" ODF	1 to 5
BF163S-XF	3/8" ODF	1 to 8

* OEM preferred and approved for use with R-410A.

LIQUID LINE FILTER DRIERS - GOLD LABEL		
Model	Connections	R22 / 410A Tons
032	1/4" SAE Male	1/4 to 1
032S	1/4" ODF	1/4 to 1
032FM	1/4" SAE Female x Male	1/4 to 1
052	1/4" SAE Male	1/2 to 1-1/2
052S	1/4" ODF	1/2 to 1-1/2
053	3/8" SAE Male	1/2 to 2
053S	3/8" ODF	1/2 to 2
082	1/4" SAE Male	1/2 to 1-1/2
082S	1/4" ODF	1/2 to 1-1/2
083	3/8" SAE Male	1 to 5
083S	3/8" ODF	1 to 5
084	1/2" SAE Male	1 to 7
084S	1/2" ODF	1 to 7
1625S	5/16" ODF	1-1/2 to 3-1/2
163	3/8" SAE Male	1 to 5
163S	3/8" ODF	1 to 5
164	1/2" SAE Male	2 to 7-1/2
164S	1/2" ODF	2 to 7-1/2
165	5/8" SAE Male	2 to 10
165S	5/8" ODF	2 to 10
303	3/8" SAE Male	2 to 5
303S	3/8" ODF	2 to 5
304	1/2" SAE Male	4 to 8
304S	1/2" ODF	4 to 8
305	5/8" SAE Male	5 to 15
305S	5/8" ODF	5 to 15
307S	7/8" ODF	5 to 20
415	5/8" SAE Male	7-1/2 to 15
415S	5/8" ODF	7-1/2 to 15
417S	7/8" ODF	7-1/2 to 20
756S	3/4" ODF	7-1/2 to 20
757S	7/8" ODF	15 to 25
759S	1-1/8" ODF	15 to 25




SLD Series

SUCTION LINE FILTER DRIERS - GOLD LABEL		
Model	Connections	R22 / 410A Tons
SLD 8-3SV HH	3/8" ODF	1/4 to 1
SLD 8-4SV HH	1/2" ODF	1/2 to 2-1/2
SLD 8-5SV HH	5/8" ODF	1 to 4
SLD 8-6SV HH	3/4" ODF	1 to 4
SLD 8-7SV HH	7/8" ODF	1 to 4
SLD 13-5SV HH	5/8" ODF	1-1/2 to 5
SLD 13-6SV HH	3/4" ODF	1-1/2 to 7
SLD 13-7SV HH	7/8" ODF	1-1/2 to 7
SLD 13-9SV HH	1-1/8" ODF	2 to 7
SLD 27-7SVHH	7/8" ODF	3 to 10
SLD 27-9SVHH	1-1/8" ODF	4 to 13
SLD 54-11SV HH	1-3/8" ODF	5 to 20
SLD 54-13SV HH	1-5/8" ODF	5 to 23

SS Series

LIQUID LINE FILTER DRIERS - SAHARA SERIES		
Model	Connections	R22 / 410A Tons
SS-053S	3/8" ODF	1 - 3
SS-083S	3/8" ODF	1 - 5
SS-163S	3/8" ODF	1 - 5

SUCTION LINE FILTER DRIERS - SAHARA SERIES		
Model	Connections	R22 / 410A Tons
SLD165-V	5/8" ODF	1 to 3-1/4
SLD166-V	3/4" ODF	1 to 3-1/4
SLD167-V	7/8" ODF	1 to 3-1/2
SLD305-V	5/8" ODF	2 to 3-1/2
SLD306-V	3/4" ODF	2 to 4-1/2
SLD307-V	7/8" ODF	2 to 5

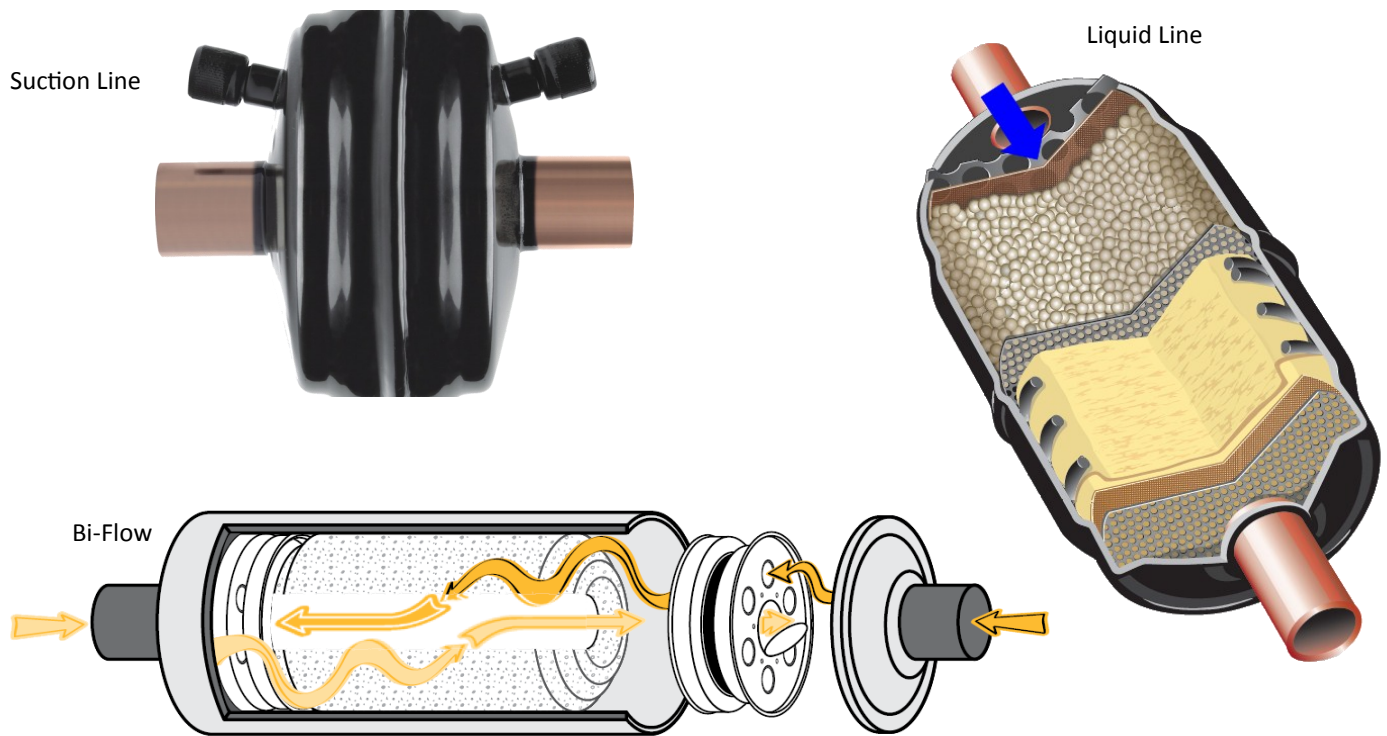

All Parker Steel Liquid Line Filter-Driers are rated at 600 PSI working pressure.

ODF are Solid copper braze fittings. SAE are nickel plated steel.

Gold Label have blend of Activated Alumina and Molecular Sieve.

"XF" and Sahara Series have 100% Molecular Sieve.

On Sweat connections, always protect the filter-drier from overheat when installing.

In general, select a filter-drier with the same connection size as the system liquid line.

When replacing a filter-drier from an existing system, always use a tubing cutter to remove the old one.