




Air Line Filtration Accessories

Bulletin 1300 - 150/USA

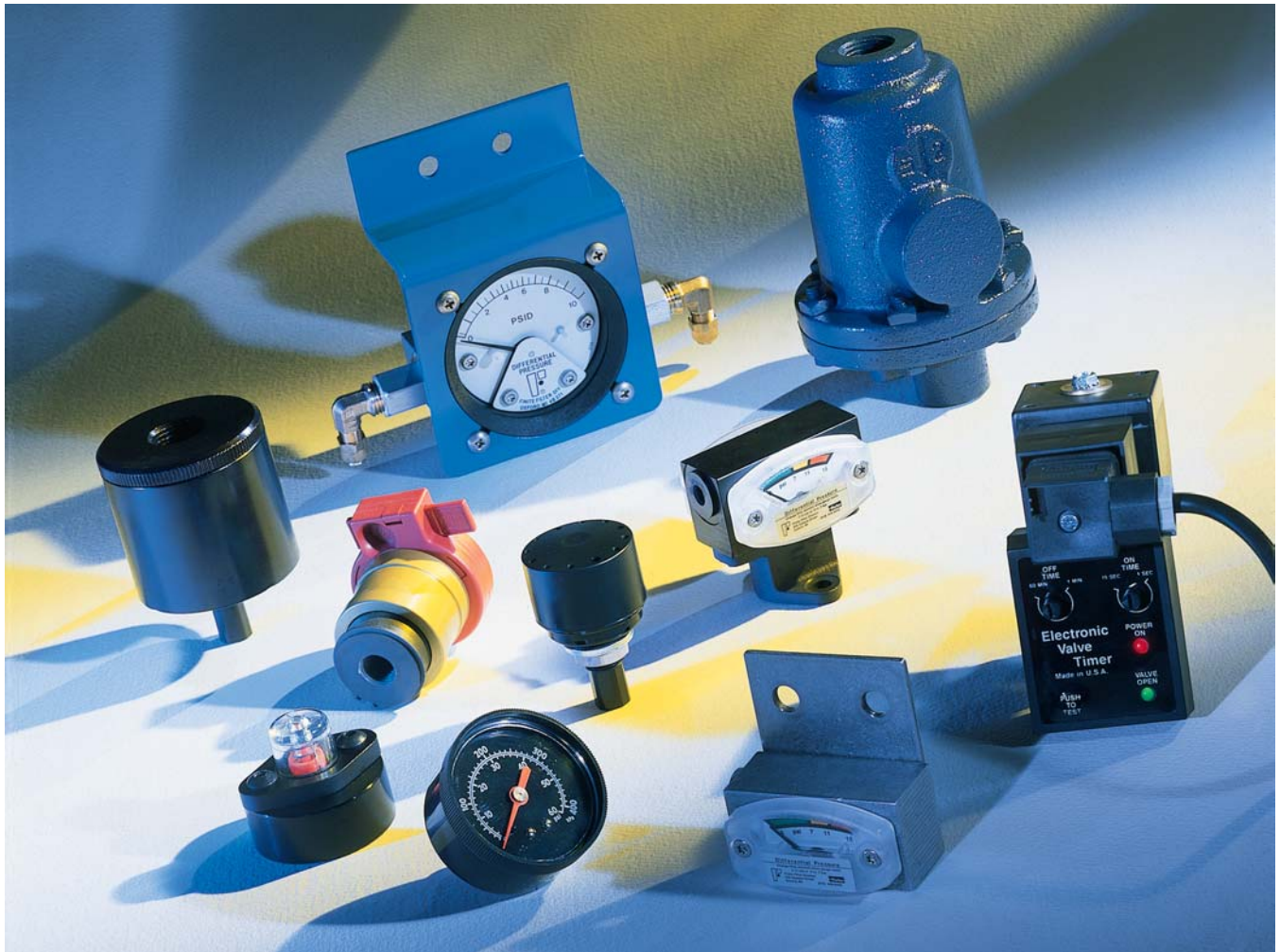

Finite®

Air Line Filtration Accessories

A comprehensive guide to products that compliment your filtration requirements




AD-12 Automatic Drain Valve (Internal)
 Temp: 175°F (79°C)
 Pressure: 250 PSIG (17 bar)
 1/8" NPT Drain Connection



DPI-25 Differential Pressure Gauge
 Temp: 200°F (88°C)
 Pressure: 5000 PSIG (340 bar)
 1/4" NPT Connections



DPI-13 Differential Pressure Indicator
 Temp: 175°F (79°C)
 Pressure: 250 PSIG (17 bar)
 1/8" NPT Connections

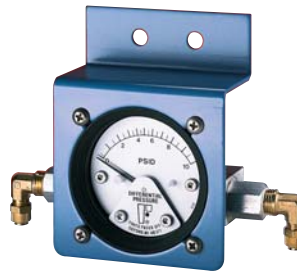

KBDPI-25 Differential Pressure Gauge
 Temp: 200°F (88°C)
 Pressure: 250 PSIG (17 bar)
 (Kit includes 1/8" and 1/4" NPT brass fittings, flexible nylon tubing and mounting bracket)



DPG-15 Differential Pressure Gauge
 Temp: 175°F (79°C)
 Pressure: 500 PSIG (34 bar)
 (Fits on pre-drilled H-Series housings only)



MS-50 Metal Sump Drain (External)
 Temp: 175°F (79°C)
 Pressure: 250 PSIG (17 bar)
 1/8" NPT Drain Connection
 1/2" NPT Inlet Connection



KBDPG-15 Differential Pressure Gauge Kit
 Temp: 200°F (93°C)
 Pressure: 250 PSIG (17 bar)
 (Kit includes 1/8" and 1/4" NPT brass fittings, flexible nylon tubing and mounting bracket)



ADT-50 Float Actuated Drain Trap
 Temp: 450°F (232°C)
 Pressure: 150 PSIG (10 bar)
 1/2" NPT Inlet Connection
 1/4" NPT Drain Connection



P781641, P781642 Pressure Gauges
 Temp: 125°F (52°C)
 Pressure: 0-60 PSIG (0-4 bar),
 0-160 PSIG (0-11 bar)



KV-2A, KV-5A, KV-6A Element Frame Kits
 (Internally mounted in all ASME housings)



VS-50 Visual Sump Drain
Temp: 125°F (52°C)
Pressure: 150 PSIG (10 bar)



MBS-1 Stainless Steel Mounting Bracket



TD-50 Adjustable Timed Drain Valve
Temp: 150°F (66°C)
Pressure: 600 PSIG (42 bar)
1/2" NPT Inlet and Outlet Connections



BK-1, BK-3 Mounting Brackets



ZLD-10 Zero Loss Drain
Temp: 35°-140°F (2°-60°C)
Pressure: 12-250 PSIG (0-17 bar)



ADS-50 Stainless Steel (304) Automatic Drain Trap
Temp: 450°F (232°C)
Pressure: 250 PSIG (17 bar)
1/2" NPT Inlet and Outlet Connections



TV-25 Timed Drain Valve
Temp: 230°F (110°C)
Pressure: 300 PSIG (20 bar)
1/4" NPT

TV-25-700 Timed Drain Valve
Temp: 210°F (99°C)
Pressure: 700 PSIG (48 bar)
1/4" NPT

TV-25-SS Timed Drain Valve (stainless steel)
Temp: 185°F (85°C)
Pressure: 200 PSIG (14 bar)
1/4" NPT

TV-50 Timed Drain Valve
Temp: 210°F (99°C)
Pressure: 300 PSIG (20 bar)
1/2" NPT

TV-50-SV Timed Drain Valve (built-in strainer valve)
Temp: 210°F (99°C)
Pressure: 300 PSIG (20 bar)
1/2" NPT

Where Used Chart

Use the chart below to find out what accessory can be used on what **Finite®** product. If you have any questions regarding accessories, please call our technical assistance department at 1-800-521-4357.

Accessory Part Number	To be used on/with . . .
AD-12	All H-Series Housings
DPI-13	For Remote Mounting
DPG-15	All H-Series Housings (Pre-drilled for DPI/DPG Option)
KBDPG-15	For Wall Mounting or on ASME Housings
DPI-25	For Remote Mounting
KBDPI-25	For Wall Mounting or on ASME Housings
MS-50	H-Series
ADT-50	Larger H-Series and ASME Housings
TV-25/TV-50	H-Series and ASME Housings
TD-50	ASME Housings
ADS-50	H-Series and ASME Housings; S3C/S4C SS Housings
KV-2A	Finite® Elements **51-280
KV-5A	Finite® Elements **85-250
KV-6A	Finite® Elements **85-360
P781641	Any Air Line Application 0-60 PSI/Finite FRL's & F12E Series
P781642	Any Air Line Application 0-160 PSI/Finite FRL's & F12E Series
MBS-1	S1R and S5R Stainless Steel Housings
BK-1	H-Series Housings up to 1/2" NPT
BK-3	H-Series Housings 3/4" and 1" NPT
VS-50	H-Series
ZLD-10	H-Series and ASME Housings



Member of



Parker Hannifin Corporation
 Filtration and Separation Division
 500 Glaspie St./P.O. Box 599
 Oxford, MI 48371
 Phone: (248) 628-6400
 (800) 521-4357
 Fax: (248) 628-1850
<http://www.parker.com/finitefilter>
 Reprinted May 2004

State of California ONLY
WARNING: Proposition 65
 The products described herein can expose you to chemicals known to the State of California to cause cancer or reproductive harm.
 For more information: www.P65Warnings.ca.gov