



FOCUSED ON THE LASER CUTTING INDUSTRY



ENGINEERING YOUR SUCCESS.

FOCUSED ON CUTTING EDGE TECHNOLOGY AND INDUSTRY EXPERTISE

When success is measured in microns, the accuracy and reliability of your equipment is vital. That's where Parker comes in.

We offer a complete range of advanced compressed air and gas solutions, precision manufactured for laser cutting. From gas generation through to filtration, chillers, dryers and pipework, we look after the entire system. And by combining specialist industry knowledge with world class engineering expertise, we are able to provide important advances in performance and efficiency that give you the edge in the marketplace.

Complete solutions for every laser cutting application

- Assist and purge gas generation and treatment
- Laser process cooling
- Efficient compressed air treatment for pneumatic automation and actuation
- Distribution systems for air and gas

Performance and reliability

Bringing proven engineering quality together with advanced technology, Parker enables constant and reliable compressed air or gas for machine operation, assist gas, cutting and purge. It means you can be confident that your machine will deliver optimum cutting accuracy, time and again.

Energy efficiency

Long term savings are built-in with Parker. We specify the most energy-efficient solutions, using innovative technology to set new standards – helping customers to meet sustainability targets and to enjoy dramatically reduced running costs over the product lifetime.

Productivity and profitability

Maximum up-time means maximum profitability. Parker equipment is designed to provide optimum performance, over a longer operational period, and with fewer costly interruptions for scheduled maintenance or break-down. Bottom line; we improve productivity, we enhance profitability, we add value for the laser cutting industry.

“Parker was able to offer a complete and unparalleled air treatment solution for our cutting machines”

General Manager,
Laser cutting machine manufacturer



FOCUSED ON THE COMPLETE SOLUTION FROM A SINGLE, INDUSTRY-LEADING MANUFACTURER


Performance. Profitability. Efficiency. Reliability. When it comes to laser cutting, Parker delivers everything you need for successful operation.



Assist and purge gas generation & treatment

Clean dry compressed air and nitrogen gas generation providing the lowest lifetime cost in the market, for unmatched profitability

- Highest output
- Highest efficiency
- Lowest maintenance
- Lowest energy consumption

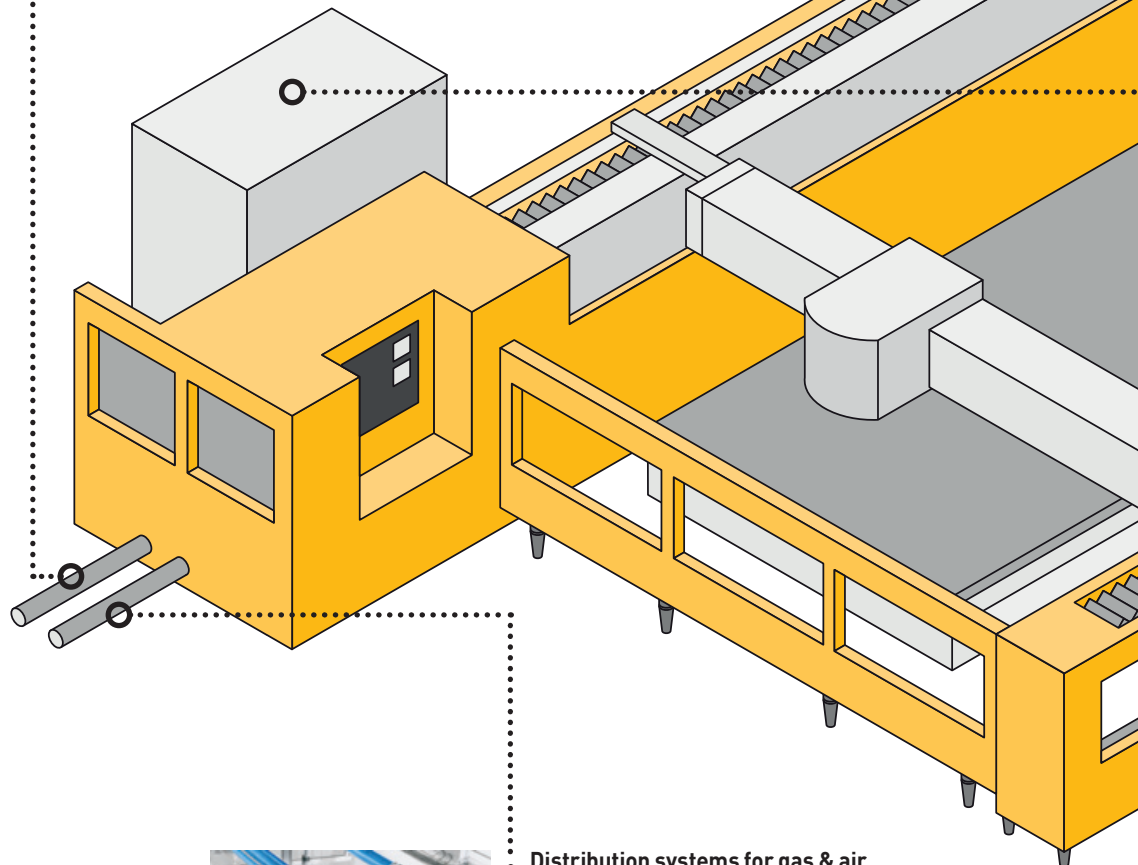

Distribution systems for gas & air

The high performance pipe system for rapid reconfiguration and maximum production flexibility

- Lightweight construction
- Corrosion resistant
- Quick-connect interlocking design
- Total system integrity






Laser process cooling

Cost efficient, versatile solution for accurate temperature control

- Precision temperature management
- Compact and flexible design
- Maximum fluid quality
- Low energy consumption

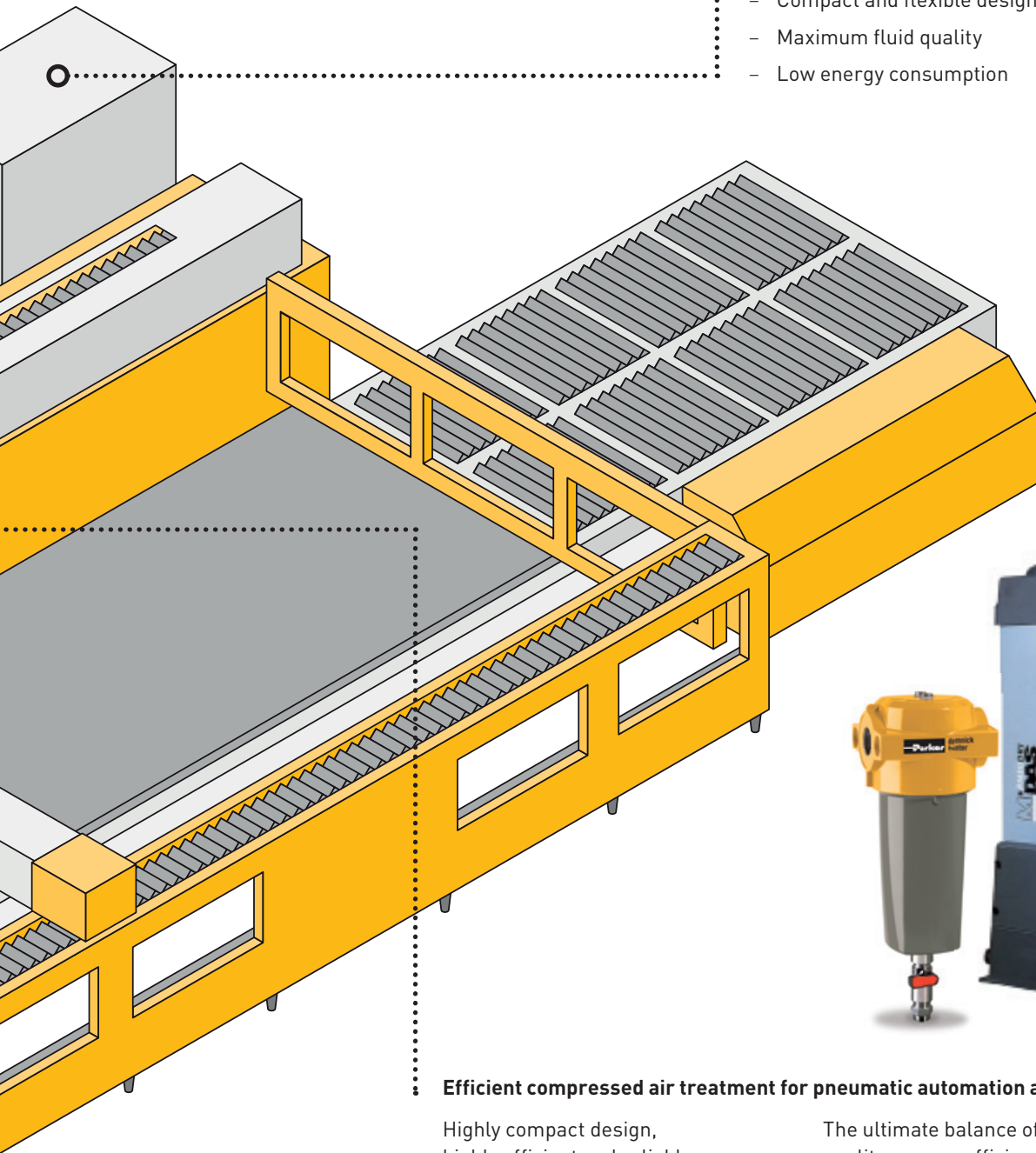

Efficient compressed air treatment for pneumatic automation and actuation

Highly compact design, highly efficient and reliable drying performance

- Reliable dry, oil-free air
- Maximum energy efficiency
- Space saving and lightweight
- Modular and flexible

The ultimate balance of air quality, energy efficiency and low lifetime cost

- Industry leading air quality
- World's highest energy efficiency
- Low cost of ownership
- Reduced CO₂ emissions

FOCUSED ON INNOVATION AND QUALITY FOR OEMS

At Parker, we work closely with customers' design teams to ensure that systems are 100% effective, right from the outset.

We bring unparalleled expertise in compressed air and gas treatment and gas generation, as well as vast technical know-how, gained at the sharp end of global manufacturing, including laser cutting. And by combining our expertise with our customers', we are able to develop better engineering solutions.

From project brief to final assembly, we work hand-in-glove with OEM partners to ensure outstanding system performance and efficiency. With world-class innovation, unique product specification and quality-assured manufacturing, Parker means success is built-in.

- Global engineering know-how, world class manufacturing expertise
- The complete compressed air and gas treatment and gas generation system design
- Custom solutions including product branding for OEM partners

Precise compressed air and gas treatment solutions for the laser cutting industry.

“Parker’s know-how and technical expertise led to a seamless integration with our systems – ensuring our customers benefit from maximum performance and reliability”

General Manager,
Laser cutting machine manufacturer





NEXT STEPS

To find out more about Parker's expertise and solutions for the laser cutting industry please call 00 800 2727 5374

Parker Worldwide

Europe, Middle East, Africa

AE – United Arab Emirates,
Dubai

Tel: +971 4 8127100
parker.me@parker.com

AT – Austria, Wiener Neustadt

Tel: +43 (0)2622 23501-0
parker.austria@parker.com

AT – Eastern Europe, Wiener
Neustadt

Tel: +43 (0)2622 23501 900
parker.easteurope@parker.com

AZ – Azerbaijan, Baku

Tel: +994 50 2233 458
parker.azerbaijan@parker.com

BE/LU – Belgium, Nivelles

Tel: +32 (0)67 280 900
parker.belgium@parker.com

BG – Bulgaria, Sofia

Tel: +359 2 980 1344
parker.bulgaria@parker.com

BY – Belarus, Minsk

Tel: +48 (0)22 573 24 00
parker.poland@parker.com

CH – Switzerland, Etoy

Tel: +41 (0)21 821 87 00
parker.switzerland@parker.com

CZ – Czech Republic, Klecany

Tel: +420 284 083 111
parker.czechrepublic@parker.com

DE – Germany, Kaarst

Tel: +49 (0)2131 4016 0
parker.germany@parker.com

DK – Denmark, Ballerup

Tel: +45 43 56 04 00
parker.denmark@parker.com

ES – Spain, Madrid

Tel: +34 902 330 001
parker.spain@parker.com

FI – Finland, Vantaa

Tel: +358 (0)20 753 2500
parker.finland@parker.com

FR – France, Contamine s/Arve

Tel: +33 (0)4 50 25 80 25
parker.france@parker.com

GR – Greece, Athens

Tel: +30 210 933 6450
parker.greece@parker.com

HU – Hungary, Budaörs

Tel: +36 23 885 470
parker.hungary@parker.com

IE – Ireland, Dublin

Tel: +353 (0)1 466 6370
parker.ireland@parker.com

IT – Italy, Corsico (MI)

Tel: +39 02 45 19 21
parker.italy@parker.com

KZ – Kazakhstan, Almaty

Tel: +7 7273 561 000
parker.easteurope@parker.com

NL – The Netherlands, Oldenzaal

Tel: +31 (0)541 585 000
parker.nl@parker.com

NO – Norway, Asker

Tel: +47 66 75 34 00
parker.norway@parker.com

PL – Poland, Warsaw

Tel: +48 (0)22 573 24 00
parker.poland@parker.com

PT – Portugal, Leca da Palmeira

Tel: +351 22 999 7360
parker.portugal@parker.com

RO – Romania, Bucharest

Tel: +40 21 252 1382
parker.romania@parker.com

RU – Russia, Moscow

Tel: +7 495 645-2156
parker.russia@parker.com

SE – Sweden, Spånga

Tel: +46 (0)8 59 79 50 00
parker.sweden@parker.com

SK – Slovakia, Banská Bystrica

Tel: +421 484 162 252
parker.slovakia@parker.com

SL – Slovenia, Novo Mesto

Tel: +386 7 337 6650
parker.slovenia@parker.com

TR – Turkey, Istanbul

Tel: +90 216 4997081
parker.turkey@parker.com

UA – Ukraine, Kiev

Tel: +48 (0)22 573 24 00
parker.poland@parker.com

UK – United Kingdom, Warwick

Tel: +44 (0)1926 317 878
parker.uk@parker.com

ZA – South Africa, Kempton Park

Tel: +27 (0)11 961 0700
parker.southafrica@parker.com

North America

CA – Canada, Milton, Ontario

Tel: +1 905 693 3000

US – USA, Cleveland

Tel: +1 216 896 3000

Asia Pacific

AU – Australia, Castle Hill

Tel: +61 (0)2-9634 7777

CN – China, Shanghai

Tel: +86 21 2899 5000

HK – Hong Kong

Tel: +852 2428 8008

IN – India, Mumbai

Tel: +91 22 6513 7081-85

JP – Japan, Tokyo

Tel: +81 (0)3 6408 3901

KR – South Korea, Seoul

Tel: +82 2 559 0400

MY – Malaysia, Shah Alam

Tel: +60 3 7849 0800

NZ – New Zealand, Mt Wellington

Tel: +64 9 574 1744

SG – Singapore

Tel: +65 6887 6300

TH – Thailand, Bangkok

Tel: +662 186 7000

TW – Taiwan, Taipei

Tel: +886 2 2298 8987

South America

AR – Argentina, Buenos Aires

Tel: +54 3327 44 4129

BR – Brazil, Sao Jose dos Campos

Tel: +55 800 727 5374

CL – Chile, Santiago

Tel: +56 2 623 1216

MX – Mexico, Toluca

Tel: +52 72 2275 4200

EMEA Product Information Centre

Free phone: 00 800 27 27 5374

(from AT, BE, CH, CZ, DE, DK, EE, ES, FI, FR, IE, IL,
IS, IT, LU, MT, NL, NO, PL, PT, RU, SE, SK, UK, ZA)

US Product Information Centre

Toll-free number: 1-800-27 27 537

www.parker.com

