


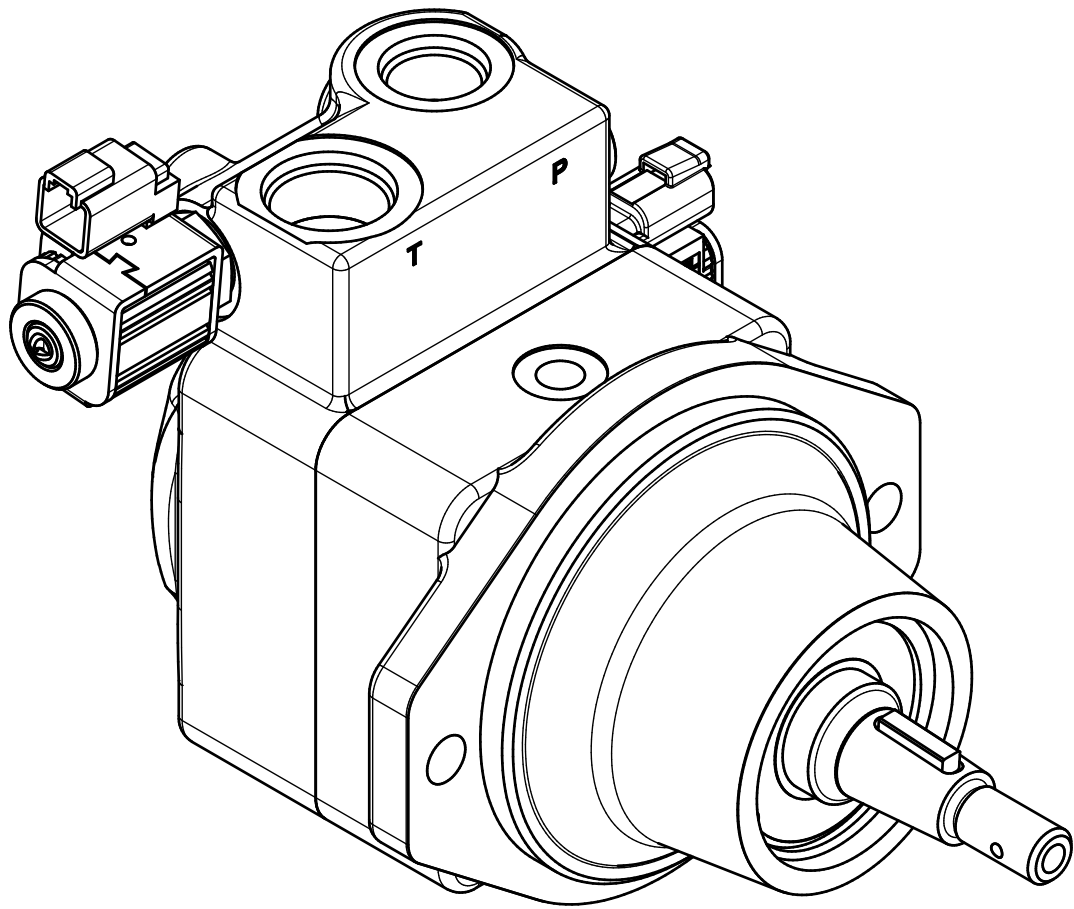

Hydraulic Motors - Service Information

M5BF

Denison Vane Technology



ENGINEERING YOUR SUCCESS.

Model No. **M5BF - 036 - W R 04 - B 1 Y - 0 R P 28**

M5BF series _____
2-bolts mounting flange, pilot Ø 135

Cam ring _____
Volumetric displacement (ml/rev)
012 = 12,5 028 = 28,0
018 = 18,0 036 = 36,0
023 = 23,0 045 = 45,0

Type of shaft _____
1 = Taper (non SAE)
2 = Keyed (SAE C)
W = Keyed cyl. (ISO G32N)

Direction of rotation (shaft end view) _____
R = Clockwise (with anti-cavitation check valve)
L = Counter-clockwise (with anti-cavitation check valve)
N = Bi-rotational (without any anti-cavitation check valve)

End cap type (See table) _____
Motor with side ports : 01, 02, 03, 04

Design letter _____
Seal class _____
1 = S1 BUNA N
5 = S5 - VITON®

Max pressure setting value
00 = For motor without pressure valve
21 = Valve set at 210 bar
28 = Valve set at 280 bar
** Customised value (please consult Parker)

Pressure valve type
0 = Without pressure valve
P = Proportional valve
M = Mechanical valve


Option
0 = No option
A = Anti-starve valve (only with end cap M & 0)
R = Reverse valve (only Y and W)


Connection variables

Uni-rotational and bi-rotational series		
Code	A & B ports	Drain port
M	4 bolts SAE flange 3/4'' with metric threads	Metric threaded port M18 x 1,5
0	4 bolts SAE flange 3/4'' with UNC threads	UNF threaded port SAE 6
Y	Metric threaded port M27 x 2	Metric threaded port M18 x 1,5
W	UNF threaded port SAE 12	UNF threaded port SAE 6


Reverse valve option			
Code	A port	B port	Drain port
Y	Metric threaded port M27 x 2	Metric threaded port M33 x 2	Metric threaded port M18 x 1,5
W	UNF threaded port SAE 12	UNF threaded port SAE 16	UNF threaded port SAE 6

Position of the ports

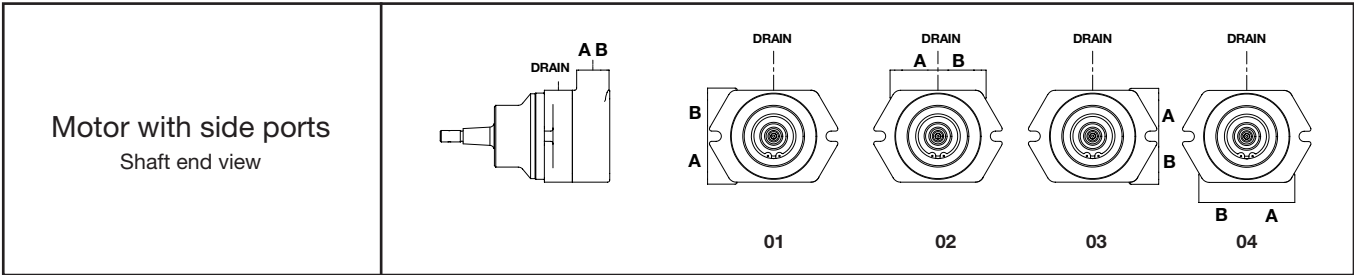


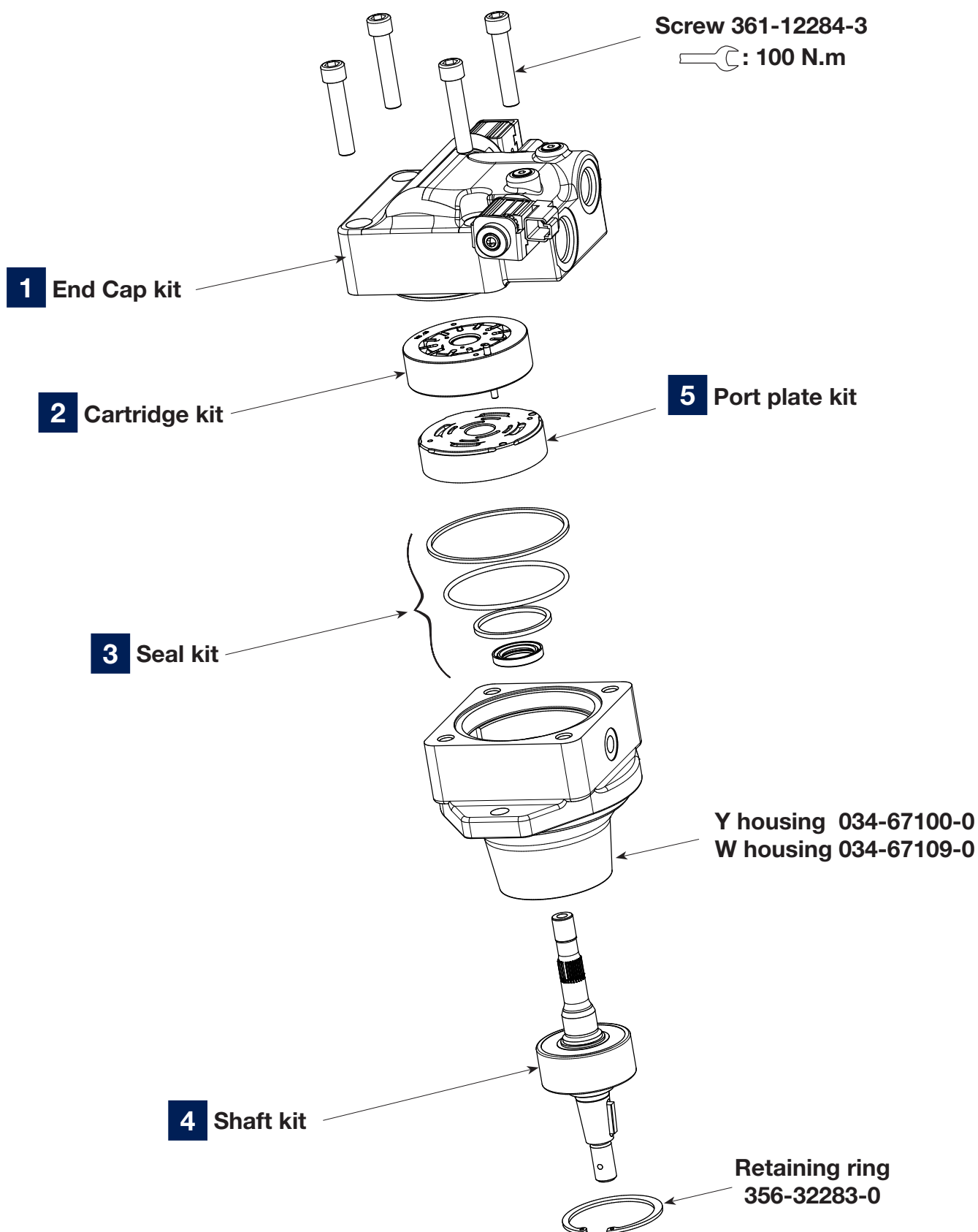

1 End cap kit / Side ports


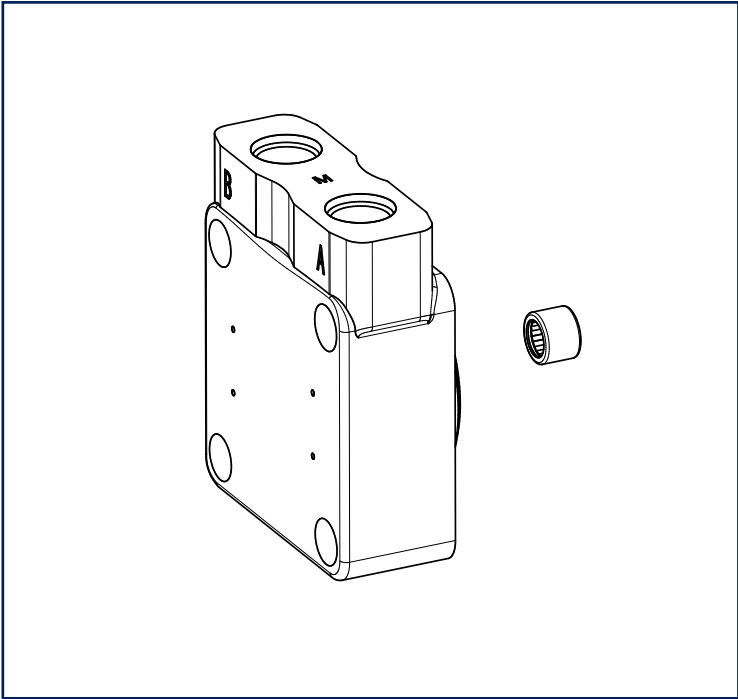


End cap kit	Code N°
M5BF - *** - * N 0* - ** M - 0 0 0 0 0	S24-94093-0
M5BF - *** - * N 0* - ** 0 - 0 0 0 0 0	S24-94094-0
M5BF - *** - * N 0* - ** Y - 0 0 0 0 0	On request
M5BF - *** - * N 0* - ** W - 0 0 0 0 0	On request

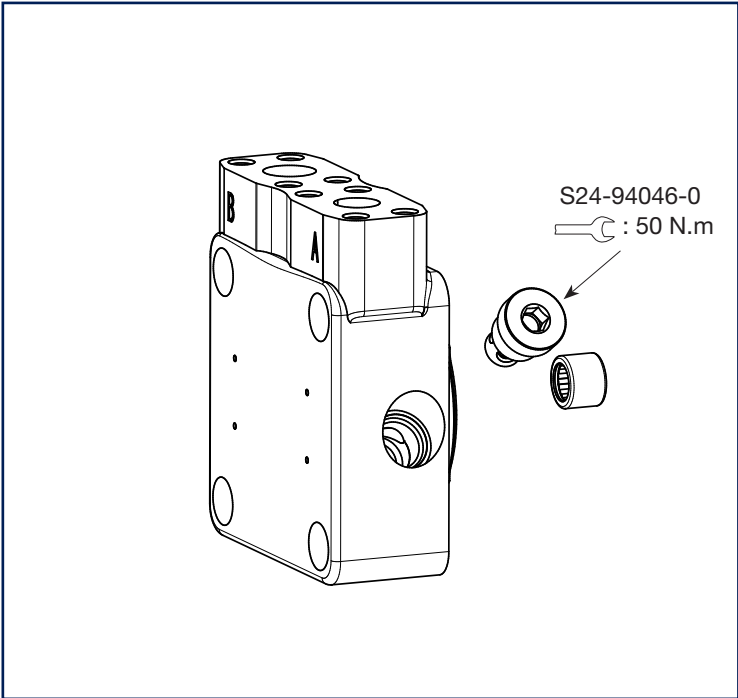


End cap kit	Code N°
M5BF - *** - * R 0* - ** M - 0 0 0 0 0	S24-940965-0
M5BF - *** - * L 0* - ** M - 0 0 0 0 0	
M5BF - *** - * R 0* - ** 0 - 0 0 0 0 0	S24-94096-0
M5BF - *** - * L 0* - ** 0 - 0 0 0 0 0	
M5BF - *** - * R 0* - ** Y - 0 0 0 0 0	On request
M5BF - *** - * L 0* - ** Y - 0 0 0 0 0	
M5BF - *** - * R 0* - ** W - 0 0 0 0 0	On request
M5BF - *** - * L 0* - ** W - 0 0 0 0 0	

 1 End cap kit / Side ports / Pressure valves

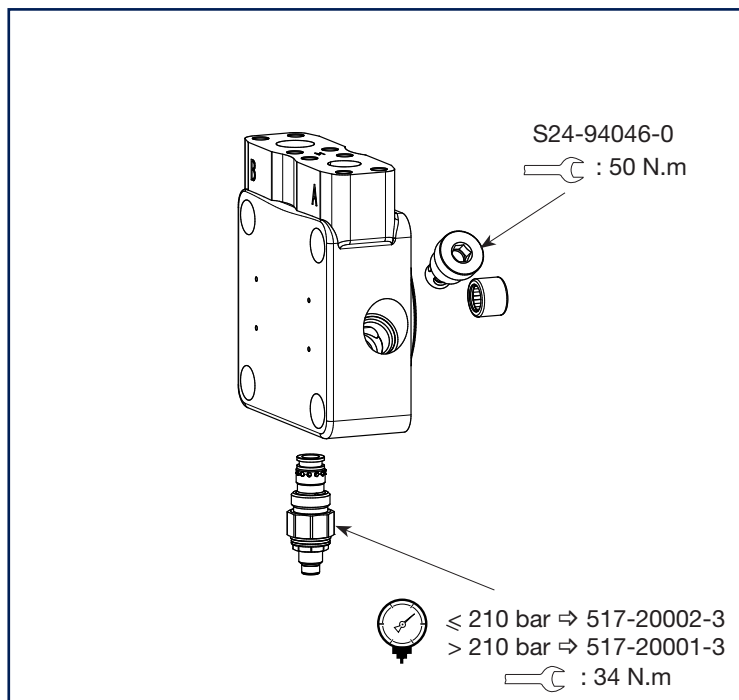


End cap kit	Code N°
M5BF - *** - * R 0* - ** M - 0 0 M 21	S54-34887-0
M5BF - *** - * L 0* - ** M - 0 0 M 21	
M5BF - *** - * R 0* - ** M - 0 0 M 28	On request
M5BF - *** - * L 0* - ** M - 0 0 M 28	
M5BF - *** - * R 0* - ** 0 - 0 0 M 21	On request
M5BF - *** - * L 0* - ** 0 - 0 0 M 21	
M5BF - *** - * R 0* - ** 0 - 0 0 M 28	On request
M5BF - *** - * L 0* - ** 0 - 0 0 M 28	
M5BF - *** - * R 0* - ** Y - 0 0 M 21	On request
M5BF - *** - * L 0* - ** Y - 0 0 M 21	
M5BF - *** - * R 0* - ** Y - 0 0 M 28	On request
M5BF - *** - * L 0* - ** Y - 0 0 M 28	
M5BF - *** - * R 0* - ** W - 0 0 M 21	On request
M5BF - *** - * L 0* - ** W - 0 0 M 21	
M5BF - *** - * R 0* - ** W - 0 0 M 28	On request
M5BF - *** - * L 0* - ** W - 0 0 M 28	

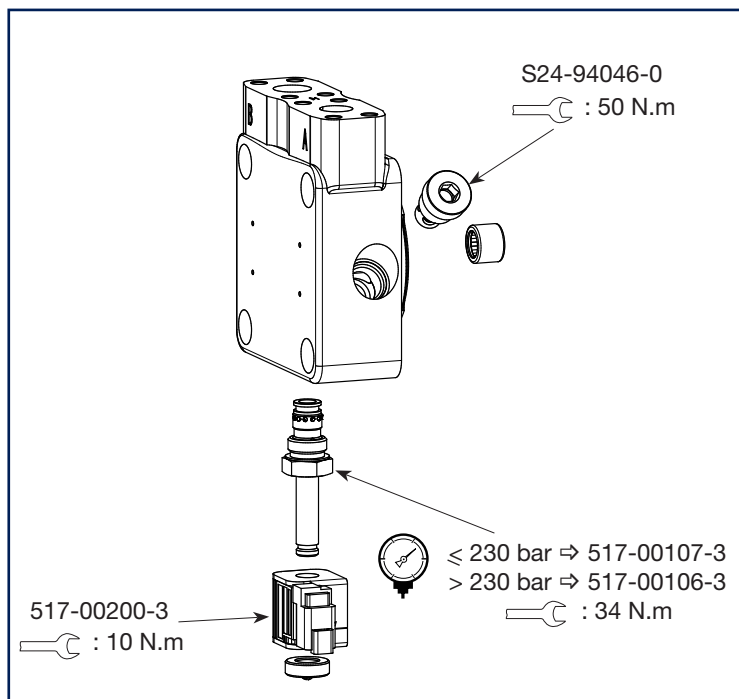



End cap kit	Code N°
M5BF - *** - * R 0* - ** M - 0 0 P 21	S54-46153-0
M5BF - *** - * L 0* - ** M - 0 0 P 21	
M5BF - *** - * R 0* - ** M - 0 0 P 28	On request
M5BF - *** - * L 0* - ** M - 0 0 P 28	
M5BF - *** - * R 0* - ** 0 - 0 0 P 21	S54-49861-0
M5BF - *** - * L 0* - ** 0 - 0 0 P 21	
M5BF - *** - * R 0* - ** 0 - 0 0 P 28	On request
M5BF - *** - * L 0* - ** 0 - 0 0 P 28	
M5BF - *** - * R 0* - ** Y - 0 0 P 21	On request
M5BF - *** - * L 0* - ** Y - 0 0 P 21	
M5BF - *** - * R 0* - ** Y - 0 0 P 28	On request
M5BF - *** - * L 0* - ** Y - 0 0 P 28	
M5BF - *** - * R 0* - ** W - 0 0 P 21	On request
M5BF - *** - * L 0* - ** W - 0 0 P 21	
M5BF - *** - * R 0* - ** W - 0 0 P 28	On request
M5BF - *** - * L 0* - ** W - 0 0 P 28	

1 End cap kit / Side ports / Anti-starve valve

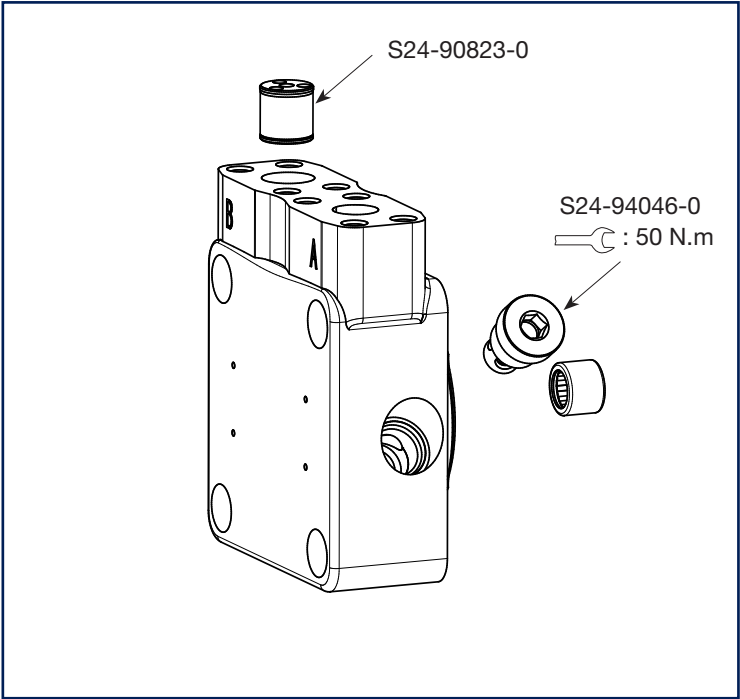


End cap kit	Code N°
M5BF - *** - * R 0* - ** M - 0 A 0 0 0	S54-34258-0
M5BF - *** - * L 0* - ** M - 0 A 0 0 0	
M5BF - *** - * R 0* - ** 0 - 0 A 0 0 0	On request
M5BF - *** - * L 0* - ** 0 - 0 A 0 0 0	

 
1 End cap kit / Side ports / Anti-starve valve / Pressure valves

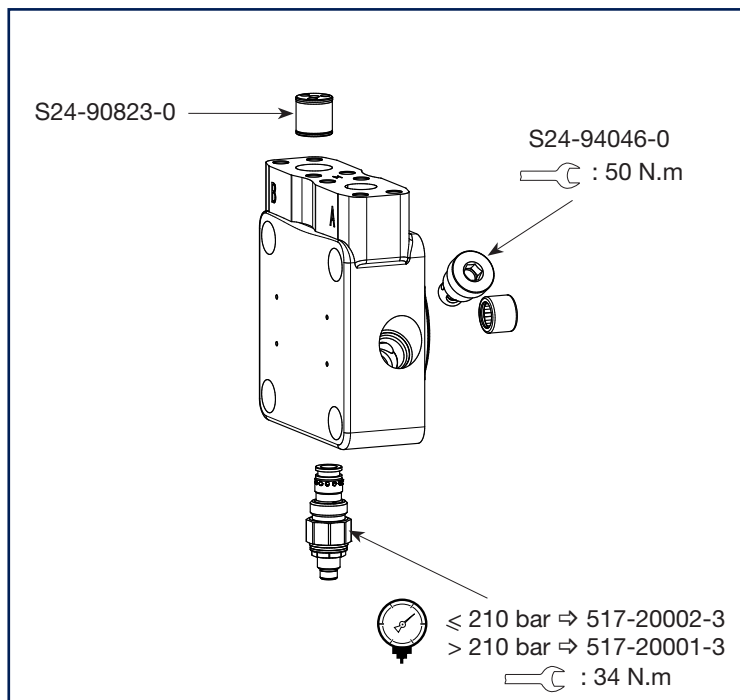


End cap kit	Code N°
M5BF - *** - * R 0* - ** M - 0 A M 21	On request
M5BF - *** - * L 0* - ** M - 0 A M 21	
M5BF - *** - * R 0* - ** M - 0 A M 28	On request
M5BF - *** - * L 0* - ** M - 0 A M 28	
M5BF - *** - * R 0* - ** 0 - 0 A M 21	On request
M5BF - *** - * L 0* - ** 0 - 0 A M 21	
M5BF - *** - * R 0* - ** 0 - 0 A M 28	On request
M5BF - *** - * L 0* - ** 0 - 0 A M 28	

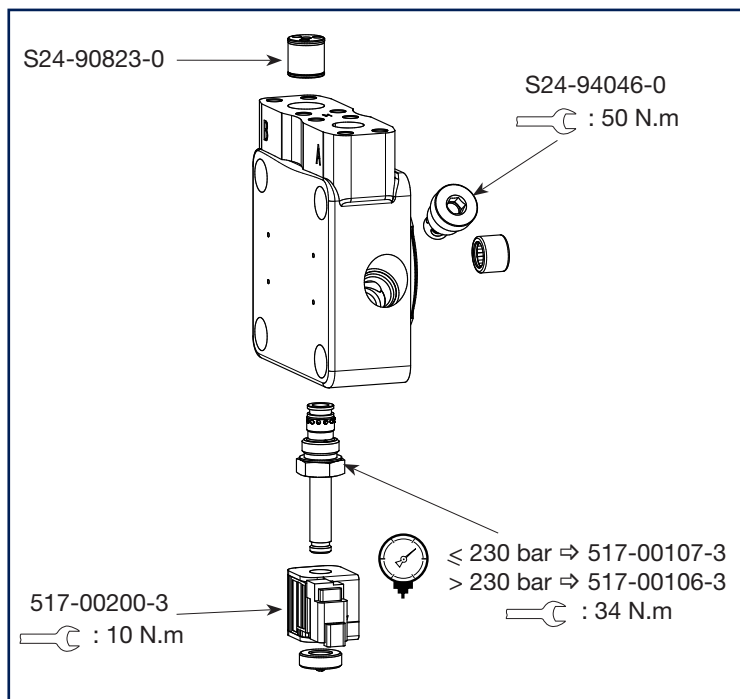


End cap kit	Code N°
M5BF - *** - * R 0* - ** M - 0 A P 21	On request
M5BF - *** - * L 0* - ** M - 0 A P 21	
M5BF - *** - * R 0* - ** M - 0 A P 28	On request
M5BF - *** - * L 0* - ** M - 0 A P 28	
M5BF - *** - * R 0* - ** 0 - 0 A P 21	On request
M5BF - *** - * L 0* - ** 0 - 0 A P 21	
M5BF - *** - * R 0* - ** 0 - 0 A P 28	On request
M5BF - *** - * L 0* - ** 0 - 0 A P 28	

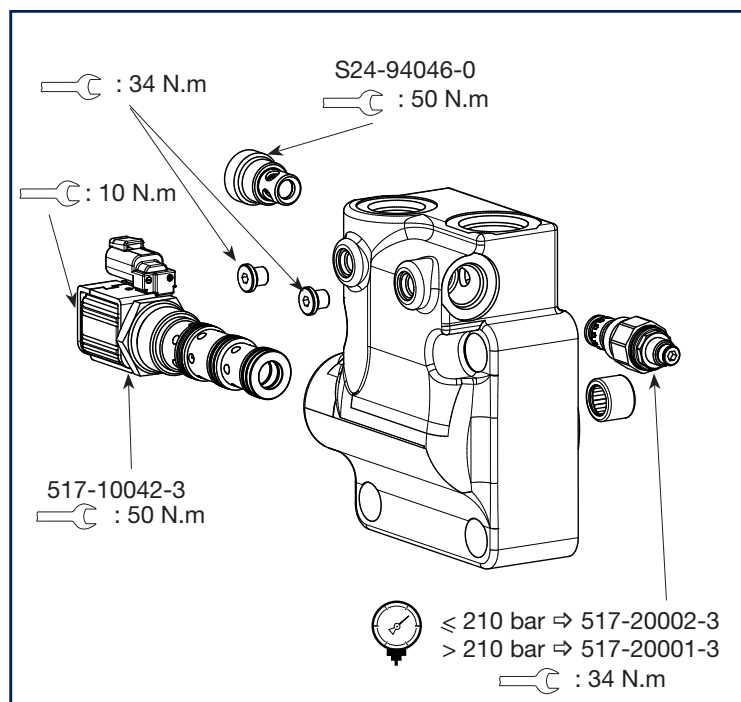1 End cap kit / Side ports / Reverse valve


End cap kit	Code N°
M5BF - *** - * R 0* - ** Y - 0 R M 21	On request
M5BF - *** - * L 0* - ** Y - 0 R M 21	On request
M5BF - *** - * R 0* - ** Y - 0 R M 28	S54-49352-0
M5BF - *** - * L 0* - ** Y - 0 R M 28	S54-49353-0
M5BF - *** - * R 0* - ** W - 0 R M 21	On request
M5BF - *** - * L 0* - ** W - 0 R M 21	On request
M5BF - *** - * R 0* - ** W - 0 R M 28	S54-47433-0
M5BF - *** - * L 0* - ** W - 0 R M 28	On request

 

End cap kit	Code N°
M5BF - *** - * R 0* - ** Y - 0 R P 21	S54-47408-0
M5BF - *** - * L 0* - ** Y - 0 R P 21	On request
M5BF - *** - * R 0* - ** Y - 0 R P 28	S54-49033-0
M5BF - *** - * L 0* - ** Y - 0 R P 28	S54-49354-0
M5BF - *** - * R 0* - ** W - 0 R P 21	S54-45115-0
M5BF - *** - * L 0* - ** W - 0 R P 21	On request
M5BF - *** - * R 0* - ** W - 0 R P 28	S54-50194-0
M5BF - *** - * L 0* - ** W - 0 R P 28	On request

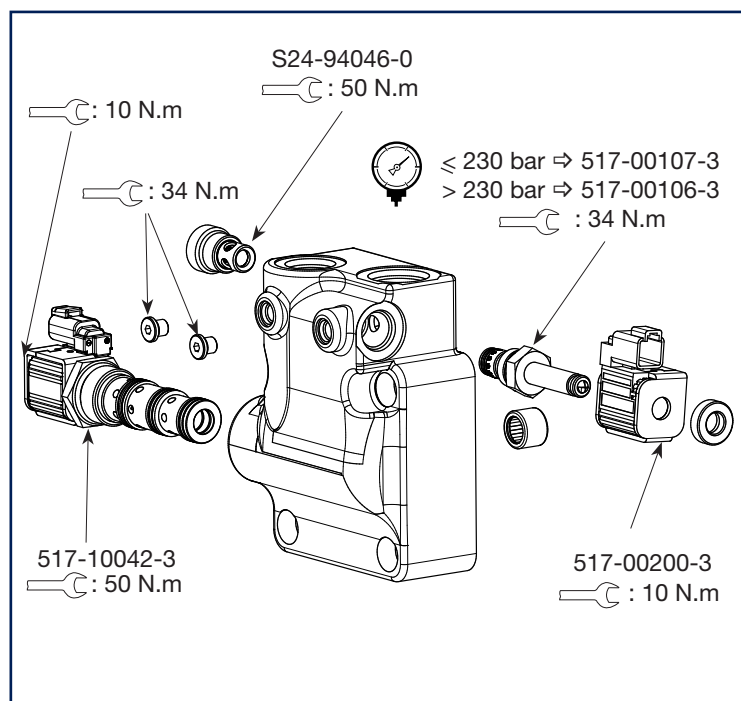


2 Cartridge kit (Preferred)

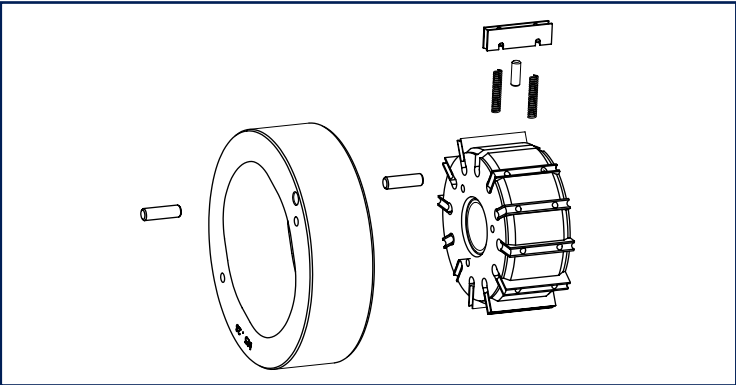


Cartridge kit	Code N°
M5BF - 012 - *** - *** - *****	S24-63500-0
M5BF - 018 - *** - *** - *****	S24-63501-0
M5BF - 023 - *** - *** - *****	S24-76436-0
M5BF - 028 - *** - *** - *****	S24-63502-0
M5BF - 036 - *** - *** - *****	S24-63503-0
M5BF - 045 - *** - *** - *****	S24-63504-0

Cartridge loose items

2 x	1 x		24 x	12 x	12 x	1 x
324-21210-0	012	034-67093-0	034-67553-0	034-67092-0	034-66991-0	S24-63495-0
	018	034-67094-0				
	023	034-67490-0				
	028	034-67095-0				
	036	034-67096-0				
	045	034-67097-0				

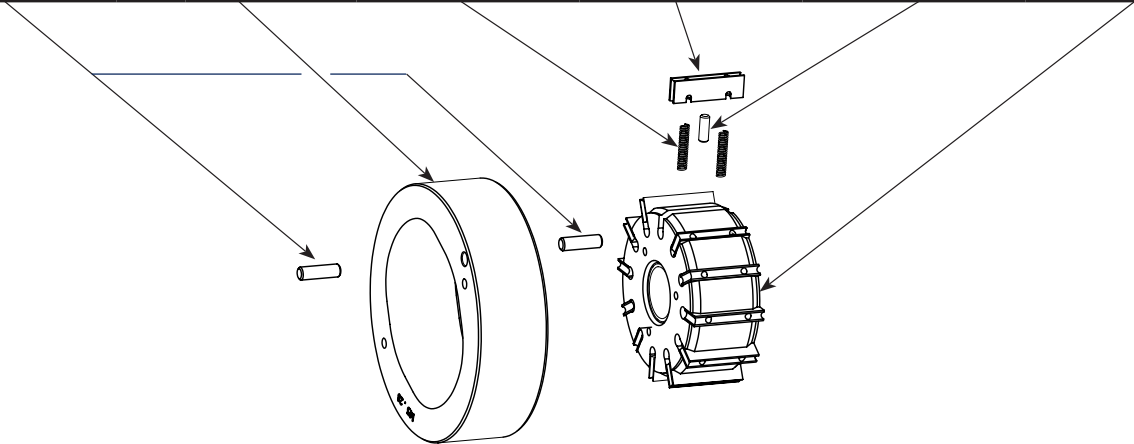


3 Seal kit

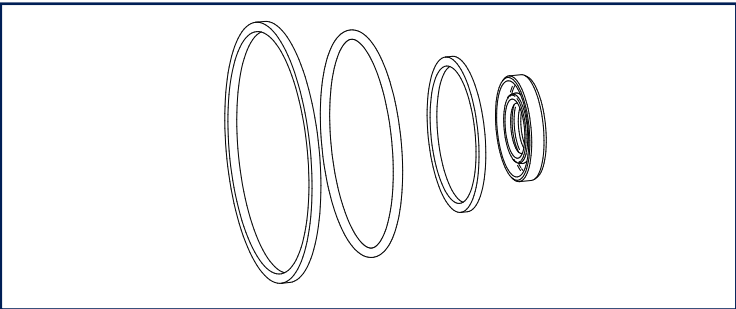


Seal kit	Code N°
M5BF - *** - *** - * 1 - *****	S24-94579-0
M5BF - *** - *** - * 5 - *****	S24-63498-5


4 Shaft kit

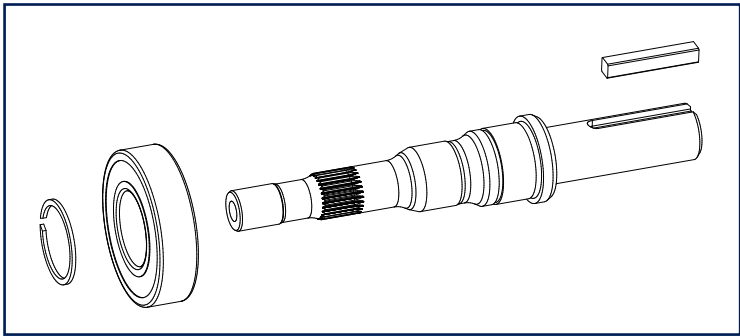


Shaft kit	Code N°
M5BF - *** - 1 *** - *** - *****	S24-63496-0
M5BF - *** - 2 *** - *** - *****	S24-68649-0
M5BF - *** - W *** - *** - *****	S24-68650-0

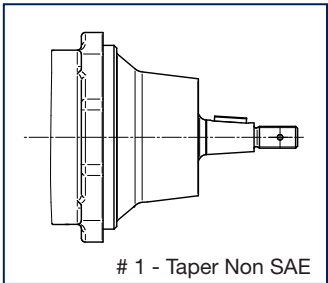

1 - Taper Non SAE

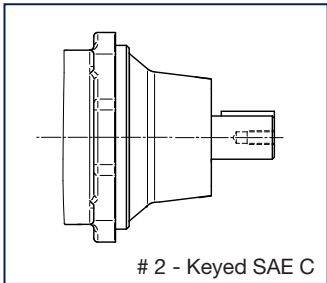


2 - Keyed SAE C

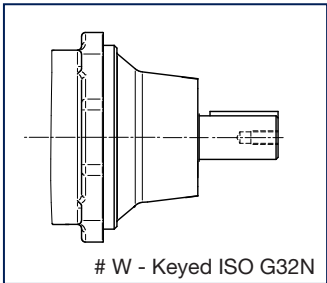

W - Keyed ISO G32N

5 Port plate kit

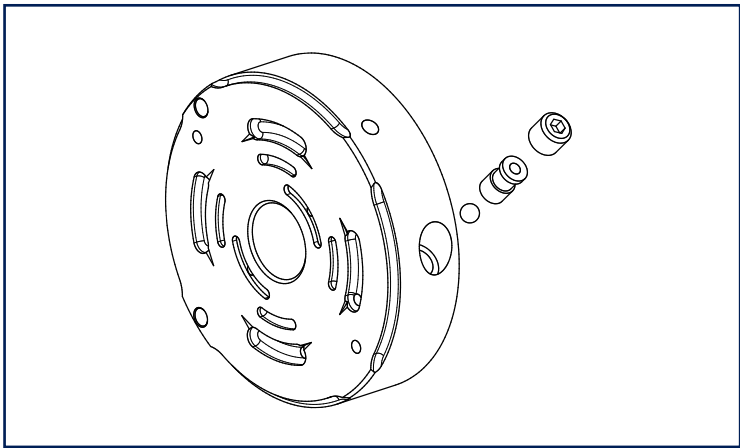

Port plate kit	Code N°
M5BF - *** - *** - *** - *****	S24-94099-0



WARNING – USER RESPONSIBILITY

FAILURE OR IMPROPER SELECTION OR IMPROPER USE OF THE PRODUCTS DESCRIBED HEREIN OR RELATED ITEMS CAN CAUSE DEATH, PERSONAL INJURY AND PROPERTY DAMAGE.

This document and other information from Parker-Hannifin Corporation, its subsidiaries and authorized distributors provide product or system options for further investigation by users having technical expertise.

The user, through its own analysis and testing, is solely responsible for making the final selection of the system and components and assuring that all performance, endurance, maintenance, safety and warning requirements of the application are met. The user must analyze all aspects of the application, follow applicable industry standards, and follow the information concerning the product in the current product catalog and in any other materials provided from Parker or its subsidiaries or authorized distributors.

To the extent that Parker or its subsidiaries or authorized distributors provide component or system options based upon data or specifications provided by the user, the user is responsible for determining that such data and specifications are suitable and sufficient for all applications and reasonably foreseeable uses of the components or systems.

Offer of Sale

Please contact your Parker representation for a detailed "Offer of Sale".

Parker Worldwide

Europe, Middle East, Africa

AE – United Arab Emirates,

Dubai

Tel: +971 4 8127100

parker.me@parker.com

AT – Austria, Wiener Neustadt

Tel: +43 (0)2622 23501-0

parker.austria@parker.com

AT – Eastern Europe, Wiener Neustadt

Tel: +43 (0)2622 23501 900

parker.easteurope@parker.com

AZ – Azerbaijan, Baku

Tel: +994 50 22 33 458

parker.azerbaijan@parker.com

BE/LU – Belgium, Nivelles

Tel: +32 (0)67 280 900

parker.belgium@parker.com

BG – Bulgaria, Sofia

Tel: +359 2 980 1344

parker.bulgaria@parker.com

BY – Belarus, Minsk

Tel: +48 (0)22 573 24 00

parker.poland@parker.com

CH – Switzerland, Etoy

Tel: +41 (0)21 821 87 00

parker.switzerland@parker.com

CZ – Czech Republic, Klecany

Tel: +420 284 083 111

parker.czechrepublic@parker.com

DE – Germany, Kaarst

Tel: +49 (0)2131 4016 0

parker.germany@parker.com

DK – Denmark, Ballerup

Tel: +45 43 56 04 00

parker.denmark@parker.com

ES – Spain, Madrid

Tel: +34 902 330 001

parker.spain@parker.com

FI – Finland, Vantaa

Tel: +358 (0)20 753 2500

parker.finland@parker.com

FR – France, Contamine s/Arve

Tel: +33 (0)4 50 25 80 25

parker.france@parker.com

GR – Greece, Athens

Tel: +30 210 933 6450

parker.greece@parker.com

HU – Hungary, Budaoers

Tel: +36 23 885 470

parker.hungary@parker.com

IE – Ireland, Dublin

Tel: +353 (0)1 466 6370

parker.ireland@parker.com

IT – Italy, Corsico (MI)

Tel: +39 02 45 19 21

parker.italy@parker.com

KZ – Kazakhstan, Almaty

Tel: +7 7273 561 000

parker.easteurope@parker.com

NL – The Netherlands, Oldenzaal

Tel: +31 (0)541 585 000

parker.nl@parker.com

NO – Norway, Asker

Tel: +47 66 75 34 00

parker.norway@parker.com

PL – Poland, Warsaw

Tel: +48 (0)22 573 24 00

parker.poland@parker.com

PT – Portugal

Tel: +351 22 999 7360

parker.portugal@parker.com

RO – Romania, Bucharest

Tel: +40 21 252 1382

parker.romania@parker.com

RU – Russia, Moscow

Tel: +7 495 645-2156

parker.russia@parker.com

SE – Sweden, Spånga

Tel: +46 (0)8 59 79 50 00

parker.sweden@parker.com

SK – Slovakia, Banská Bystrica

Tel: +421 484 162 252

parker.slovakia@parker.com

SL – Slovenia, Novo Mesto

Tel: +386 7 337 6650

parker.slovenia@parker.com

TR – Turkey, Istanbul

Tel: +90 216 4997081

parker.turkey@parker.com

UA – Ukraine, Kiev

Tel: +48 (0)22 573 24 00

parker.poland@parker.com

UK – United Kingdom, Warwick

Tel: +44 (0)1926 317 878

parker.uk@parker.com

ZA – South Africa, Kempton Park

Tel: +27 (0)11 961 0700

parker.southafrica@parker.com

North America

CA – Canada, Milton, Ontario

Tel: +1 905 693 3000

US – USA, Cleveland

(industrial)

Tel: +1 216 896 3000

US – USA, Elk Grove Village

(mobile)

Tel: +1 847 258 6200

Asia Pacific

AU – Australia, Castle Hill

Tel: +61 (0)2-9634 7777

CN – China, Shanghai

Tel: +86 21 2899 5000

HK – Hong Kong

Tel: +852 2428 8008

ID – Indonesia, Tangerang

Tel: +62 21 7588 1906

IN – India, Mumbai

Tel: +91 22 6513 7081-85

JP – Japan, Fujisawa

Tel: +81 (0)4 6635 3050

KR – South Korea, Seoul

Tel: +82 2 559 0400

MY – Malaysia, Shah Alam

Tel: +60 3 7849 0800

NZ – New Zealand, Mt Wellington

Tel: +64 9 574 1744

SG – Singapore

Tel: +65 6887 6300

TH – Thailand, Bangkok

Tel: +662 186 7000

TW – Taiwan, New Taipei City

Tel: +886 2 2298 8987

VN – Vietnam, Ho Chi Minh City

Tel: +84 8 3999 1600

South America

AR – Argentina, Buenos Aires

Tel: +54 3327 44 4129

BR – Brazil, Cachoeirinha RS

Tel: +55 51 3470 9144

CL – Chile, Santiago

Tel: +56 2 623 1216

MX – Mexico, Toluca

Tel: +52 72 2275 4200

Ed. 2016-04-04

EMEA Product Information Centre

Free phone: 00 800 27 27 5374

(from AT, BE, CH, CZ, DE, DK, EE, ES, FI, FR, IE, IL, IS, IT, LU, MT, NL, NO, PL, PT, RU, SE, SK, UK, ZA)

US Product Information Centre

Toll-free number: 1-800-27 27 537

www.parker.com

Your local authorized Parker distributor

