



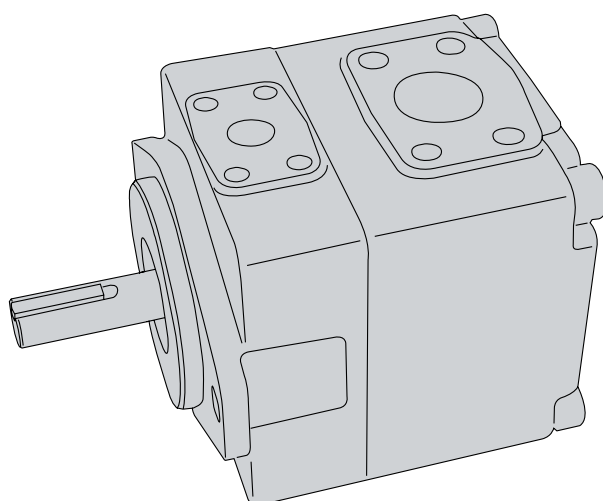

Handbook - Hydraulic Pumps

Epumps Spare Parts

Denison Vane Technology

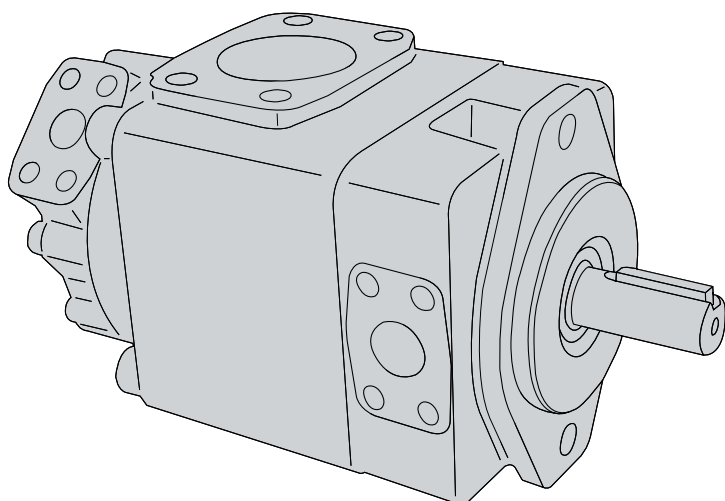

ENGINEERING YOUR SUCCESS.

Range of pumps

Key sheet n° 21 pump type : T7B	3
Key sheet n° 31 pump type : T7BS	4
Key sheet n° 81 pump type : T7D	5
Key sheet n° 91 pump type : T7DS	6
Key sheet n° 121 pump type : T7ES	7
Key sheet n° 131 pump type : T7BB	8
Key sheet n° 141 pump type : T7BBS	9
Key sheet n° 221 pump type : T7DB	10
Key sheet n° 231 pump type : T7DBS	11
Key sheet n° 285 pump type : T7DD	12
Key sheet n° 286 pump type : T7DDS	13



WARNING – USER RESPONSIBILITY

FAILURE OR IMPROPER SELECTION OR IMPROPER USE OF THE PRODUCTS DESCRIBED HEREIN OR RELATED ITEMS CAN CAUSE DEATH, PERSONAL INJURY AND PROPERTY DAMAGE.

This document and other information from Parker-Hannifin Corporation, its subsidiaries and authorized distributors provide product or system options for further investigation by users having technical expertise.

The user, through its own analysis and testing, is solely responsible for making the final selection of the system and components and assuring that all performance, endurance, maintenance, safety and warning requirements of the application are met. The user must analyze all aspects of the application, follow applicable industry standards, and follow the information concerning the product in the current product catalog and in any other materials provided from Parker or its subsidiaries or authorized distributors.


To the extent that Parker or its subsidiaries or authorized distributors provide component or system options based upon data or specifications provided by the user, the user is responsible for determining that such data and specifications are suitable and sufficient for all applications and reasonably foreseeable uses of the components or systems.

Offer of Sale

Please contact your Parker representation for a detailed "Offer of Sale".

Key Sheet N° 21

Ex. T7B - E10 - 2 R 00 - A 1 00

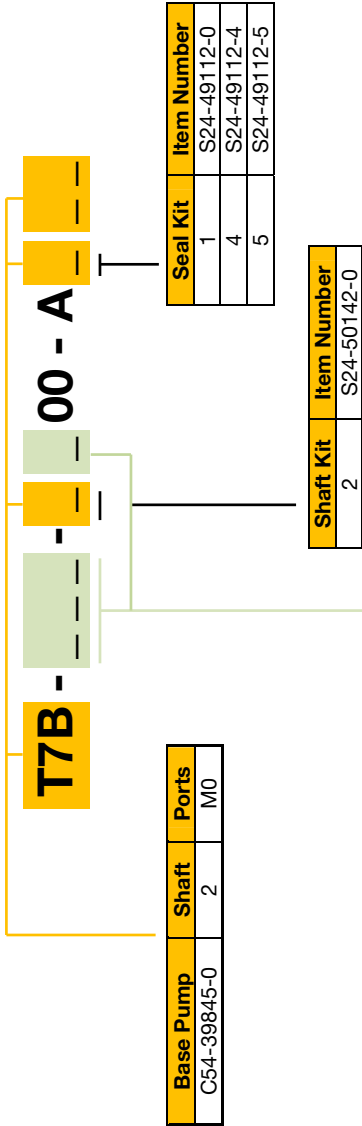


Volumetric displacement	Cartridge kit	
	R (CW)	L (CCW)
E03	S54-47925-0	S54-47926-0
E04	S54-47927-0	S54-47928-0
E05	S54-47929-0	S54-47930-0
E06	S54-47931-0	S54-47932-0
E07	S54-47933-0	S54-47934-0
E08	S54-47935-0	S54-47936-0
E09	S54-47937-0	S54-47938-0
E10	S54-47939-0	S54-47940-0
E11	S54-47941-0	S54-47942-0
E12	S54-47943-0	S54-47944-0
E14	S54-47945-0	S54-47946-0
E15	S54-47947-0	S54-47948-0

Features of the base pump

Key Sheet N° 31

Ex. T7BS - E10 - 1 R 00 - A 1 00

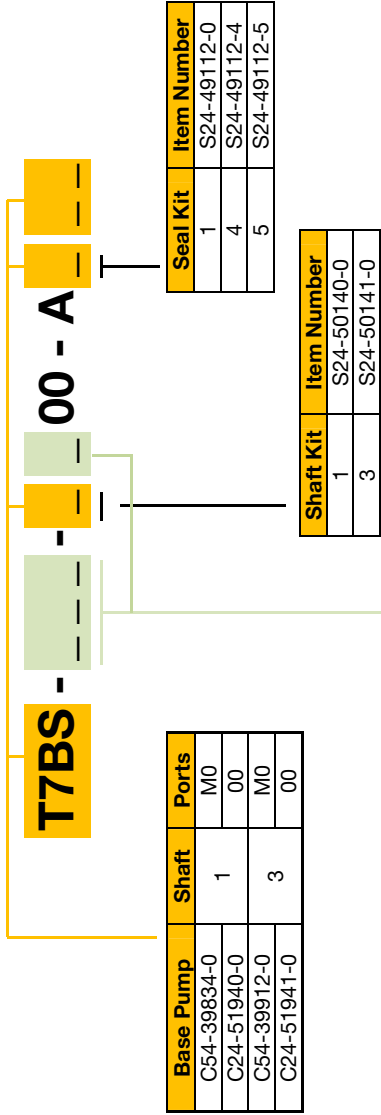


Volumetric displacement	Cartridge kit	
	R (CW)	L (CCW)
E03	S54-47925-0	S54-47926-0
E04	S54-47927-0	S54-47928-0
E05	S54-47929-0	S54-47930-0
E06	S54-47931-0	S54-47932-0
E07	S54-47933-0	S54-47934-0
E08	S54-47935-0	S54-47936-0
E09	S54-47937-0	S54-47938-0
E10	S54-47939-0	S54-47940-0
E11	S54-47941-0	S54-47942-0
E12	S54-47943-0	S54-47944-0
E14	S54-47945-0	S54-47946-0
E15	S54-47947-0	S54-47948-0

Features of the base pump

Key Sheet N° 81


Ex. T7D - E42 - 5 R 00 - A 1 00

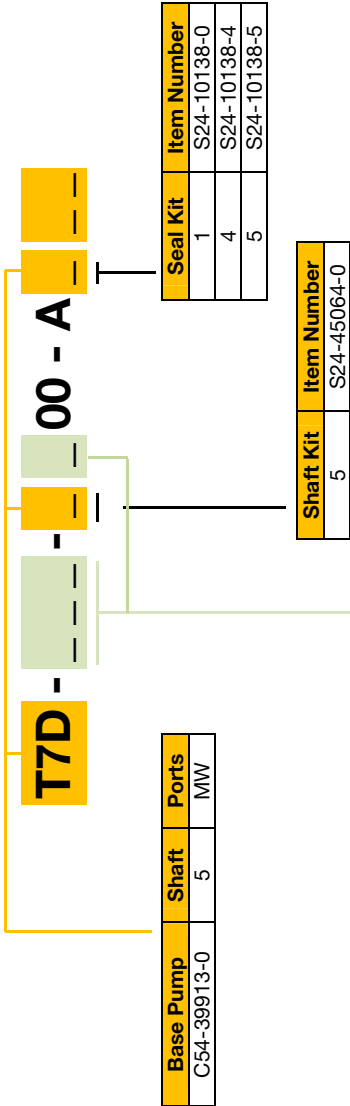

Features of the base pump

Key Sheet N° 91

Ex. T7DS - E42 - 1 R 00 - A 1 00

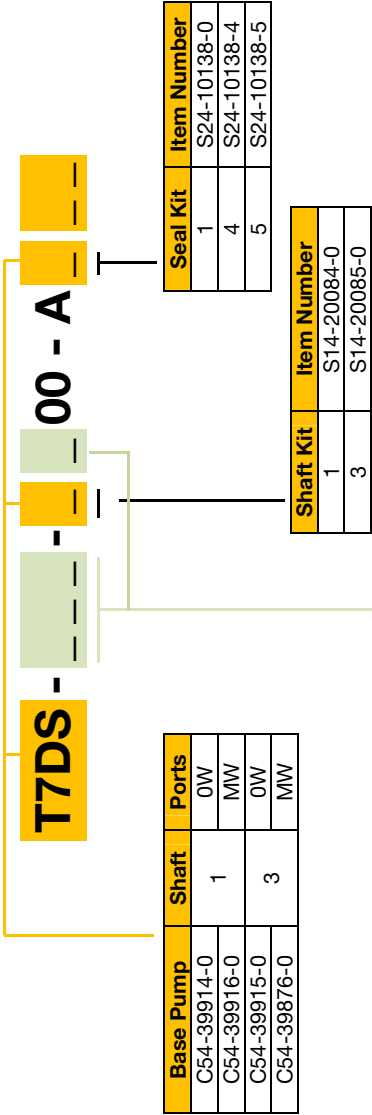


Volumetric displacement	Cartridge kit	
	R (CW)	L (CCW)
E14	S54-48922-0	S54-48923-0
E17	S54-48924-0	S54-48925-0
E20	S54-48926-0	S54-48927-0
E22	S54-48928-0	S54-48929-0
E24	S54-48930-0	S54-48931-0
E28	S54-48932-0	S54-48933-0
E31	S54-48934-0	S54-48935-0
E35	S54-48936-0	S54-48937-0
E38	S54-48938-0	S54-48939-0
E42	S54-48940-0	S54-48941-0

Features of the base pump

Key Sheet N° 121

Ex. T7ES - E72 - 1 R 00 - A 1 M0

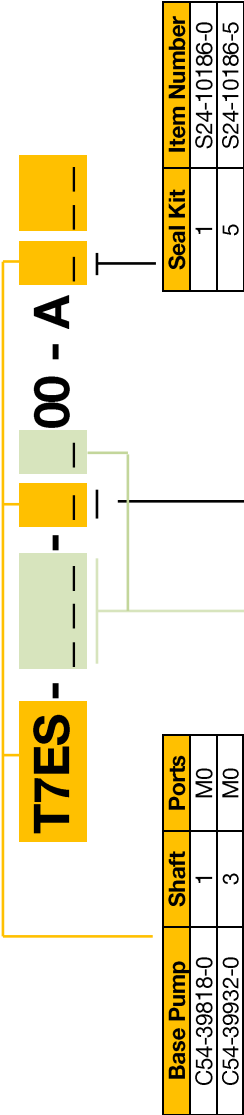


Volumetric displacement	Cartridge kit	
	R (CW)	L (CCW)
E45	S54-51018-0	S54-51019-0
E50	S54-51020-0	S54-51021-0
E52	S54-51022-0	S54-51023-0
E54	S54-51024-0	S54-51025-0
E57	S54-51026-0	S54-51027-0
E62	S54-51028-0	S54-51029-0
E66	S54-51030-0	S54-51031-0
E72	S54-51032-0	S54-51033-0

Features of the base pump

Key Sheet N° 131

Ex. T7BB - E10 - E03 - 1R 00 - A 1 M1

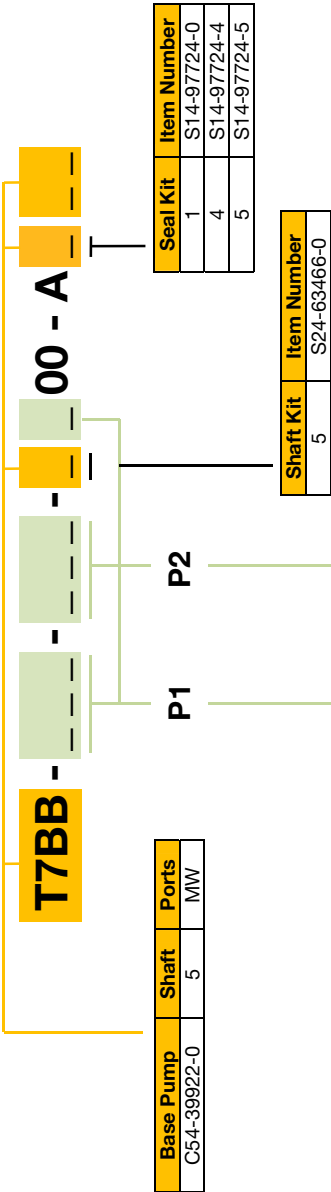


Volumetric displacement	Cartridge kit P1	
	R (CW)	L (CCW)
E03	S54-47949-0	S54-47950-0
E04	S54-47951-0	S54-47952-0
E05	S54-47953-0	S54-47954-0
E06	S54-47955-0	S54-47956-0
E07	S54-47957-0	S54-47958-0
E08	S54-47959-0	S54-47960-0
E09	S54-47961-0	S54-47962-0
E10	S54-47963-0	S54-47964-0
E11	S54-47965-0	S54-47966-0
E12	S54-47967-0	S54-47968-0
E14	S54-47969-0	S54-47970-0
E15	S54-47971-0	S54-47972-0

Volumetric displacement	Cartridge kit P2	
	R (CW)	L (CCW)
E03	S54-47973-0	S54-47974-0
E04	S54-47975-0	S54-47976-0
E05	S54-47977-0	S54-47978-0
E06	S54-47979-0	S54-47980-0
E07	S54-47981-0	S54-47982-0
E08	S54-47983-0	S54-47984-0
E09	S54-47985-0	S54-47986-0
E10	S54-47987-0	S54-47988-0
E11	S54-47989-0	S54-47990-0
E12	S54-47991-0	S54-47992-0
E14	S54-47993-0	S54-47994-0
E15	S54-47995-0	S54-47996-0

Features of the base pump

Key Sheet N° 141

Ex. T7BBS - E10 - E03 - 1 R 00 - A 1 00

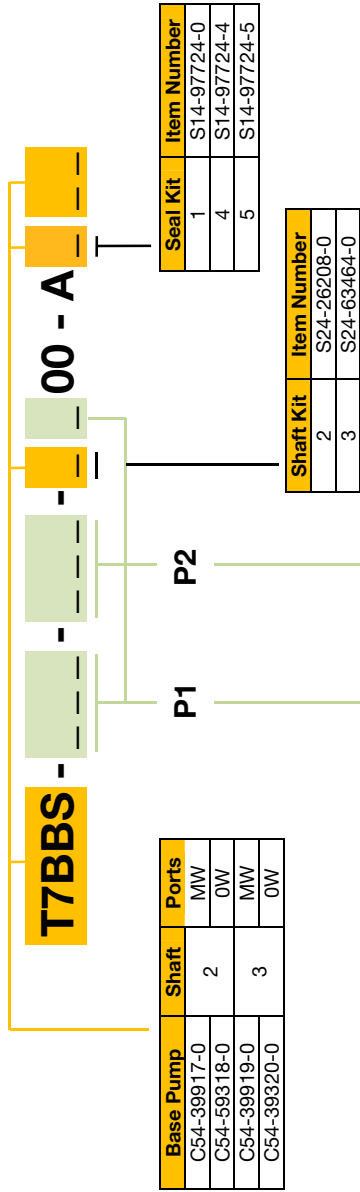


Volumetric displacement	Cartridge kit P1	
	R (CW)	L (CCW)
E03	S54-47949-0	S54-47950-0
E04	S54-47951-0	S54-47952-0
E05	S54-47953-0	S54-47954-0
E06	S54-47955-0	S54-47956-0
E07	S54-47957-0	S54-47958-0
E08	S54-47959-0	S54-47960-0
E09	S54-47961-0	S54-47962-0
E10	S54-47963-0	S54-47964-0
E11	S54-47965-0	S54-47966-0
E12	S54-47967-0	S54-47968-0
E14	S54-47969-0	S54-47970-0
E15	S54-47971-0	S54-47972-0

Volumetric displacement	Cartridge kit P2	
	R (CW)	L (CCW)
E03	S54-47973-0	S54-47974-0
E04	S54-47975-0	S54-47976-0
E05	S54-47977-0	S54-47978-0
E06	S54-47979-0	S54-47980-0
E07	S54-47981-0	S54-47982-0
E08	S54-47983-0	S54-47984-0
E09	S54-47985-0	S54-47986-0
E10	S54-47987-0	S54-47988-0
E11	S54-47989-0	S54-47990-0
E12	S54-47991-0	S54-47992-0
E14	S54-47993-0	S54-47994-0
E15	S54-47995-0	S54-47996-0

Features of the base pump

Ex. T7DB - E45 - E10 - 1 R 00 - A 1 M1

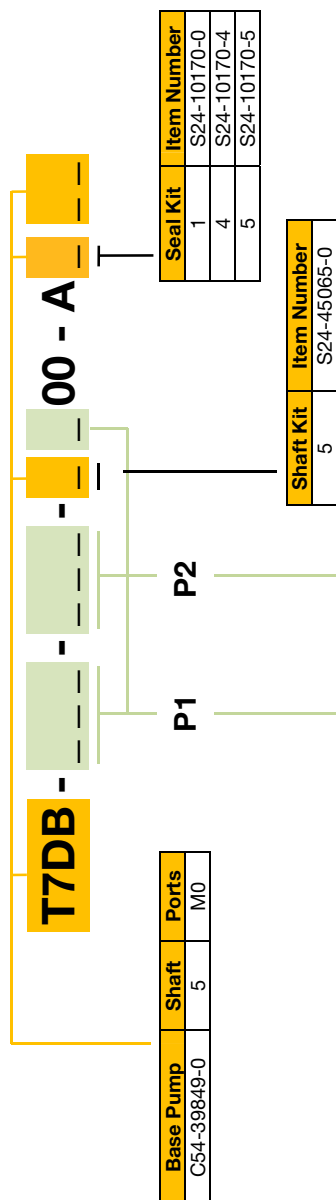


Volumetric displacement	Cartridge kit P1	
	R (CW)	L (CCW)
E14	S54-48942-0	S54-48943-0
E17	S54-48944-0	S54-48945-0
E20	S54-48946-0	S54-48947-0
E22	S54-48948-0	S54-48949-0
E24	S54-48950-0	S54-48951-0
E28	S54-48952-0	S54-48953-0
E31	S54-48954-0	S54-48955-0
E35	S54-48956-0	S54-48957-0
E38	S54-48958-0	S54-48959-0
E42	S54-48960-0	S54-48961-0

Volumetric displacement	Cartridge kit P2	
	R (CW)	L (CCW)
E03	S54-49289-0	S54-49290-0
E04	S54-49291-0	S54-49292-0
E05	S54-49293-0	S54-49294-0
E06	S54-49295-0	S54-49296-0
E07	S54-49163-0	S54-49297-0
E08	S54-49298-0	S54-49299-0
E09	S54-49300-0	S54-49301-0
E10	S54-49302-0	S54-49303-0
E11	S54-49304-0	S54-49305-0
E12	S54-49306-0	S54-49307-0
E14	S54-49308-0	S54-49309-0
E15	S54-49310-0	S54-49311-0

100%

Key Sheet N° 231

Ex. T7DBS - E42 - E10 - 1R 00 - A 1 00

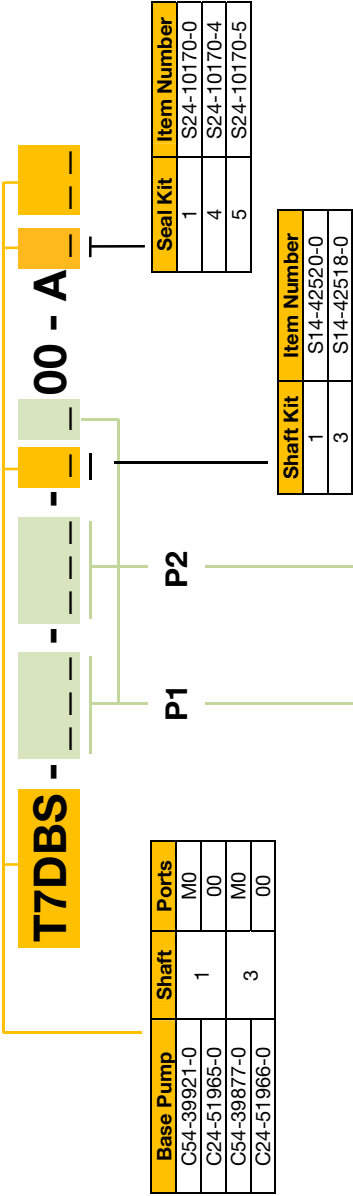


Volumetric displacement	Cartridge kit P1	
	R (CW)	L (CCW)
E14	S54-48942-0	S54-48943-0
E17	S54-48944-0	S54-48945-0
E20	S54-48946-0	S54-48947-0
E22	S54-48948-0	S54-48949-0
E24	S54-48950-0	S54-48951-0
E28	S54-48952-0	S54-48953-0
E31	S54-48954-0	S54-48955-0
E35	S54-48956-0	S54-48957-0
E38	S54-48958-0	S54-48959-0
E42	S54-48960-0	S54-48961-0

Volumetric displacement	Cartridge kit P2	
	R (CW)	L (CCW)
E03	S54-49289-0	S54-49290-0
E04	S54-49291-0	S54-49292-0
E05	S54-49293-0	S54-49294-0
E06	S54-49295-0	S54-49296-0
E07	S54-49163-0	S54-49297-0
E08	S54-49298-0	S54-49299-0
E09	S54-49300-0	S54-49301-0
E10	S54-49302-0	S54-49303-0
E11	S54-49304-0	S54-49305-0
E12	S54-49306-0	S54-49307-0
E14	S54-49308-0	S54-49309-0
E15	S54-49310-0	S54-49311-0

Features of the base pump

Key Sheet N° 285


Ex. T7DD - E42 - E20 - 1 R 00 - A 1 00

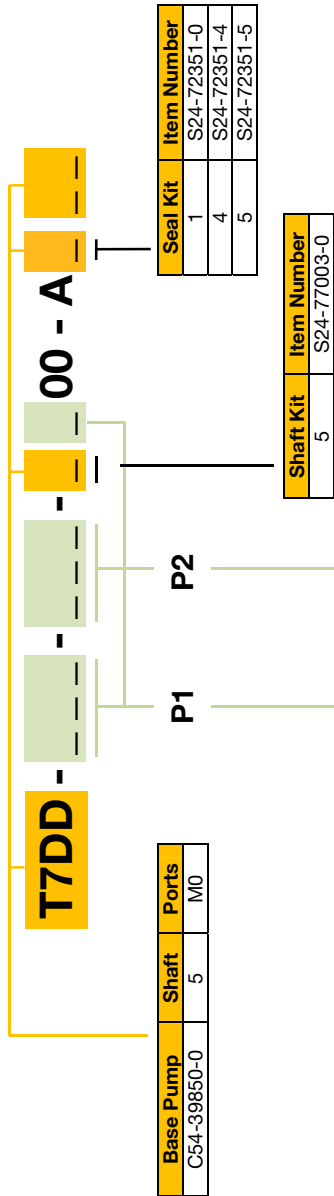

Features of the base pump

Key Sheet N° 286

Ex. T7DDS - E42 - E20 - 1R 00 - A 1 00

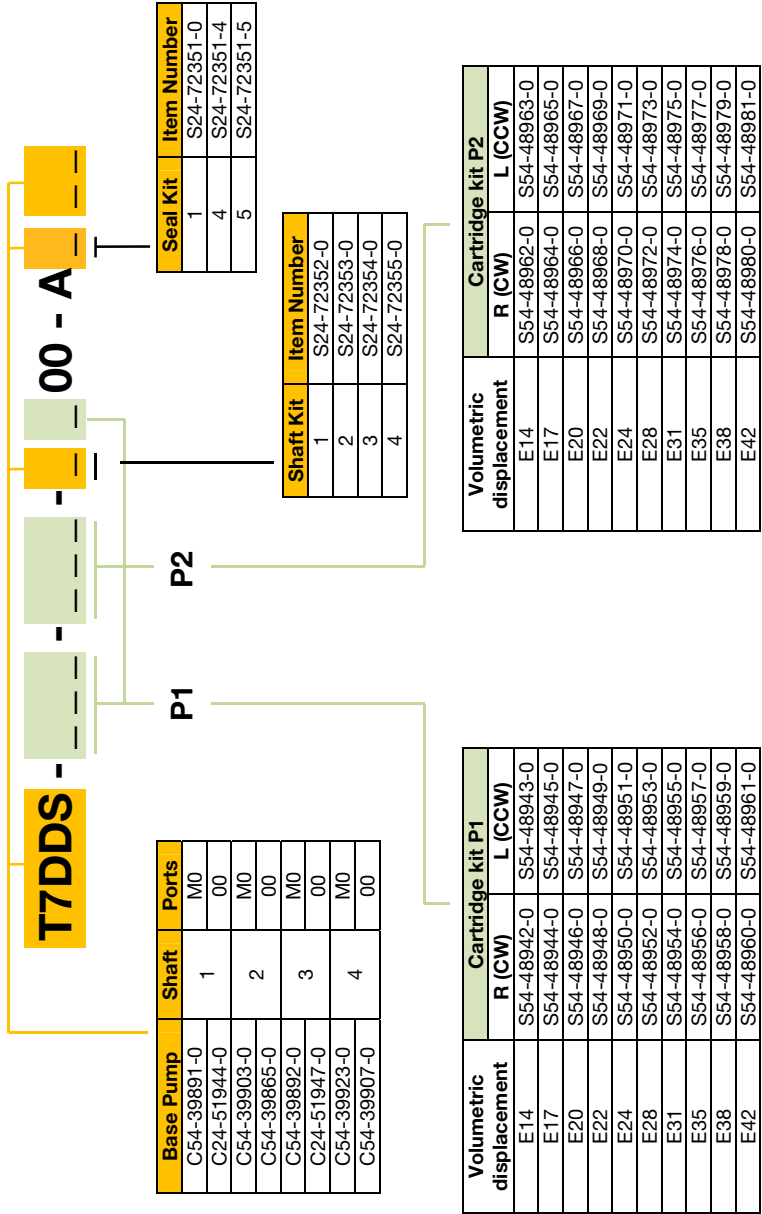

Features of the base pump

Parker Worldwide

Europe, Middle East, Africa

AE – United Arab Emirates,

Dubai

Tel: +971 4 8127100

parker.me@parker.com

AT – Austria, Wiener Neustadt

Tel: +43 (0)2622 23501-0

parker.austria@parker.com

AT – Eastern Europe, Wiener Neustadt

Tel: +43 (0)2622 23501 900

parker.easteurope@parker.com

AZ – Azerbaijan, Baku

Tel: +994 50 22 33 458

parker.azerbaijan@parker.com

BE/LU – Belgium, Nivelles

Tel: +32 (0)67 280 900

parker.belgium@parker.com

BG – Bulgaria, Sofia

Tel: +359 2 980 1344

parker.bulgaria@parker.com

BY – Belarus, Minsk

Tel: +48 (0)22 573 24 00

parker.poland@parker.com

CH – Switzerland, Etoy

Tel: +41 (0)21 821 87 00

parker.switzerland@parker.com

CZ – Czech Republic, Klecany

Tel: +420 284 083 111

parker.czechrepublic@parker.com

DE – Germany, Kaarst

Tel: +49 (0)2131 4016 0

parker.germany@parker.com

DK – Denmark, Ballerup

Tel: +45 43 56 04 00

parker.denmark@parker.com

ES – Spain, Madrid

Tel: +34 902 330 001

parker.spain@parker.com

FI – Finland, Vantaa

Tel: +358 (0)20 753 2500

parker.finland@parker.com

FR – France, Contamine s/Arve

Tel: +33 (0)4 50 25 80 25

parker.france@parker.com

GR – Greece, Athens

Tel: +30 210 933 6450

parker.greece@parker.com

HU – Hungary, Budaoers

Tel: +36 23 885 470

parker.hungary@parker.com

IE – Ireland, Dublin

Tel: +353 (0)1 466 6370

parker.ireland@parker.com

IT – Italy, Corsico (MI)

Tel: +39 02 45 19 21

parker.italy@parker.com

KZ – Kazakhstan, Almaty

Tel: +7 7273 561 000

parker.easteurope@parker.com

NL – The Netherlands, Oldenzaal

Tel: +31 (0)541 585 000

parker.nl@parker.com

NO – Norway, Asker

Tel: +47 66 75 34 00

parker.norway@parker.com

PL – Poland, Warsaw

Tel: +48 (0)22 573 24 00

parker.poland@parker.com

PT – Portugal

Tel: +351 22 999 7360

parker.portugal@parker.com

RO – Romania, Bucharest

Tel: +40 21 252 1382

parker.romania@parker.com

RU – Russia, Moscow

Tel: +7 495 645-2156

parker.russia@parker.com

SE – Sweden, Spånga

Tel: +46 (0)8 59 79 50 00

parker.sweden@parker.com

SK – Slovakia, Banská Bystrica

Tel: +421 484 162 252

parker.slovakia@parker.com

SL – Slovenia, Novo Mesto

Tel: +386 7 337 6650

parker.slovenia@parker.com

TR – Turkey, Istanbul

Tel: +90 216 4997081

parker.turkey@parker.com

UA – Ukraine, Kiev

Tel: +48 (0)22 573 24 00

parker.poland@parker.com

UK – United Kingdom, Warwick

Tel: +44 (0)1926 317 878

parker.uk@parker.com

ZA – South Africa, Kempton Park

Tel: +27 (0)11 961 0700

parker.southafrica@parker.com

North America

CA – Canada, Milton, Ontario

Tel: +1 905 693 3000

US – USA, Cleveland

(industrial)

Tel: +1 216 896 3000

US – USA, Elk Grove Village

(mobile)

Tel: +1 847 258 6200

Asia Pacific

AU – Australia, Castle Hill

Tel: +61 (0)2-9634 7777

CN – China, Shanghai

Tel: +86 21 2899 5000

HK – Hong Kong

Tel: +852 2428 8008

ID – Indonesia, Tangerang

Tel: +62 21 7588 1906

IN – India, Mumbai

Tel: +91 22 6513 7081-85

JP – Japan, Fujisawa

Tel: +81 (0)4 6635 3050

KR – South Korea, Seoul

Tel: +82 2 559 0400

MY – Malaysia, Shah Alam

Tel: +60 3 7849 0800

NZ – New Zealand, Mt Wellington

Tel: +64 9 574 1744

SG – Singapore

Tel: +65 6887 6300

TH – Thailand, Bangkok

Tel: +662 186 7000

TW – Taiwan, New Taipei City

Tel: +886 2 2298 8987

VN – Vietnam, Ho Chi Minh City

Tel: +84 8 3999 1600

South America

AR – Argentina, Buenos Aires

Tel: +54 3327 44 4129

BR – Brazil, Cachoeirinha RS

Tel: +55 51 3470 9144

CL – Chile, Santiago

Tel: +56 2 623 1216

MX – Mexico, Toluca

Tel: +52 72 2275 4200

Ed. 2016-04-04

EMEA Product Information Centre

Free phone: 00 800 27 27 5374

(from AT, BE, CH, CZ, DE, DK, EE, ES, FI, FR, IE, IL, IS, IT, LU, MT, NL, NO, PL, PT, RU, SE, SK, UK, ZA)

US Product Information Centre

Toll-free number: 1-800-27 27 537

www.parker.com

Your local authorized Parker distributor

