

Specifications:

Height: 17.2" (43.68 cm)

Width: 10.61" (26.95 cm)

Depth: 9.3" (23.61 cm)

Weight: 9.3 lbs (4.2 kg)

Ports: 1 7/8-12 UN-2B SAE O-ring Thread

Service Clearance (Bottom): 11.0" (27.94 cm)

Max Airflow: 50 CFM (1416 LM)

Max Engine Rating: 1000 HP (745 KW)

Note: Open system CV assemblies do not include a visual restriction indicator.





Hose Fittings sold separately -
See parts section

Create a Part Number

Housing Type	Filtration Rating	Bypass Type *	Filtration Type	Flow Direction
Open Crankcase Ventilation Filter	CV Model Up to 50 CFM - 1000HP	Non-Bypass Assembly	High Density Media	Left Side - Inlet Right Side - Inlet
CV	120	01	-08	L R

* If plugged: Non-Bypass assemblies will experience increased pressure on oil pan and non-pressurized engine ports.

Dimensions:

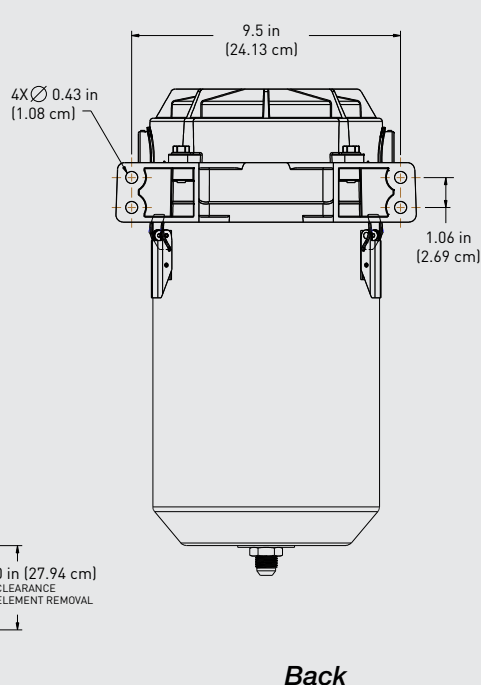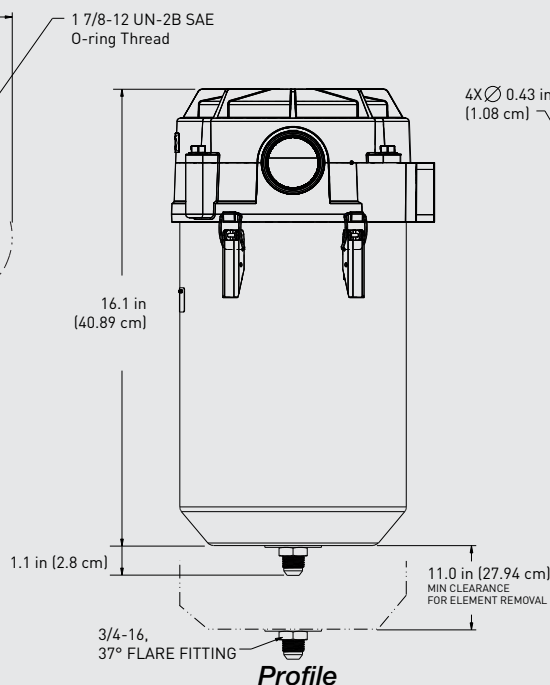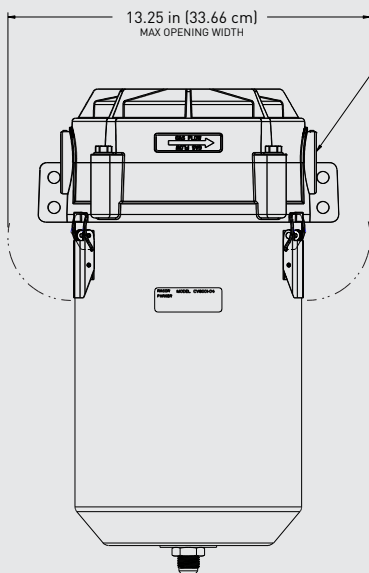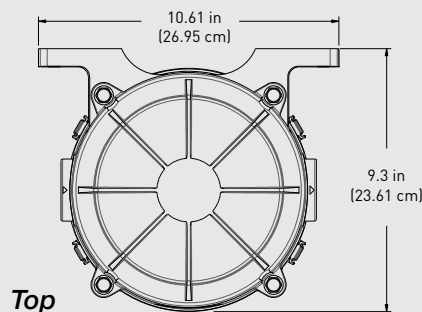


ASSEMBLY	DESCRIPTION
CV12001-08L	Open System; Up to 50 CFM/1000 HP; Non-Bypass; High Density Media; Left Inlet
CV12001-08R	Open System; Up to 50 CFM/1000 HP; Non-Bypass; High Density Media; Right Inlet



PARTS

CV Series - CV12001

 
1



1A



 1B



1C



1D



1E

Part #

Description

1A

CV12001 Head Assembly (Non-Bypass Assy.)

1B

CV12001 Diaphragm

1C

CV Valve (Non-Bypass Assy.)

1D

Housing Gasket

1E

Head Assembly Bracket

2A

CV Housing Gasket

2B

CV Filter O-ring

2C

CCV55222-12-08

CV12001 Replacement Element - High Density -
Includes 2A & 2B

3A

CCV55613-08

CV12001 Conversion Kit - *Includes 2A, 2B, 2C (-08),
and 5A*

3B

CCV55071

Drain Kit - 1/2" I.D. x 3' Hose, Check Valve, (2) Swivel
Fitting

Available Fittings, Hose, Fittings + Hose Kits (Not Shown)

NOTE: Initial Install Requires Fittings & Hose; See Brochure 7790 for requirements

4A

CCV55218

Inlet/Outlet Fitting - 1 1/2" OD Hose Barb to 1 7/8" SAE

4B

CV1112-01-C

Inlet/Outlet Hose - 1 1/2" ID Hose (Per Ft.)

4C

CCV55067

Hose/Fitting Kit - (2) 1-1/2" fittings, (1) 1-1/2" ID x 10 foot
hose, (1) bushing reducer, (4) clamps and (4) ties

CCV55068

Hose/Fitting Kit - (2) 1-1/2" fittings, (1) 1-1/2" Tee fitting,
(1) 1-1/2" ID x 12 foot hose, (2) bushing reducers,
(8) clamps and (8) ties

CCV55069

Hose/Fitting Kit - (2) 1-1/2" fittings,
(1) 1-1/2" ID x 5 foot hose w/2" cuff, (1) bushing reducer,
(1) 1-1/2" ID x 5 foot hose, (4) clamps and (4) ties

Accessories and Parts Available (Not Shown)

5A

CCV55374

Heavy-Duty Wear Spacer - *Protects element from
excessive vibrations*

5B

CCV55463-24


CCV Heater Kit - 24v DC (200w)

5C

CCV55615-01

Electronic Remote Filter Gauge Kit

 
2



2A




2B

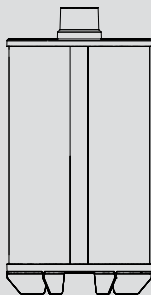


2C

3

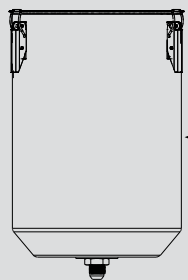

3A

 

3B



Online Link
CCV Product Selector

RSLO387_CUT_CV12001 (03/25 Rev B)

Questions? Email: racortech@parker.com Phone: 800-344-3286 News: www.racornnews.com