


LAB PUMP SELECTION & TUBING SIZE GUIDE

WHICH SHOULD YOU CHOOSE?

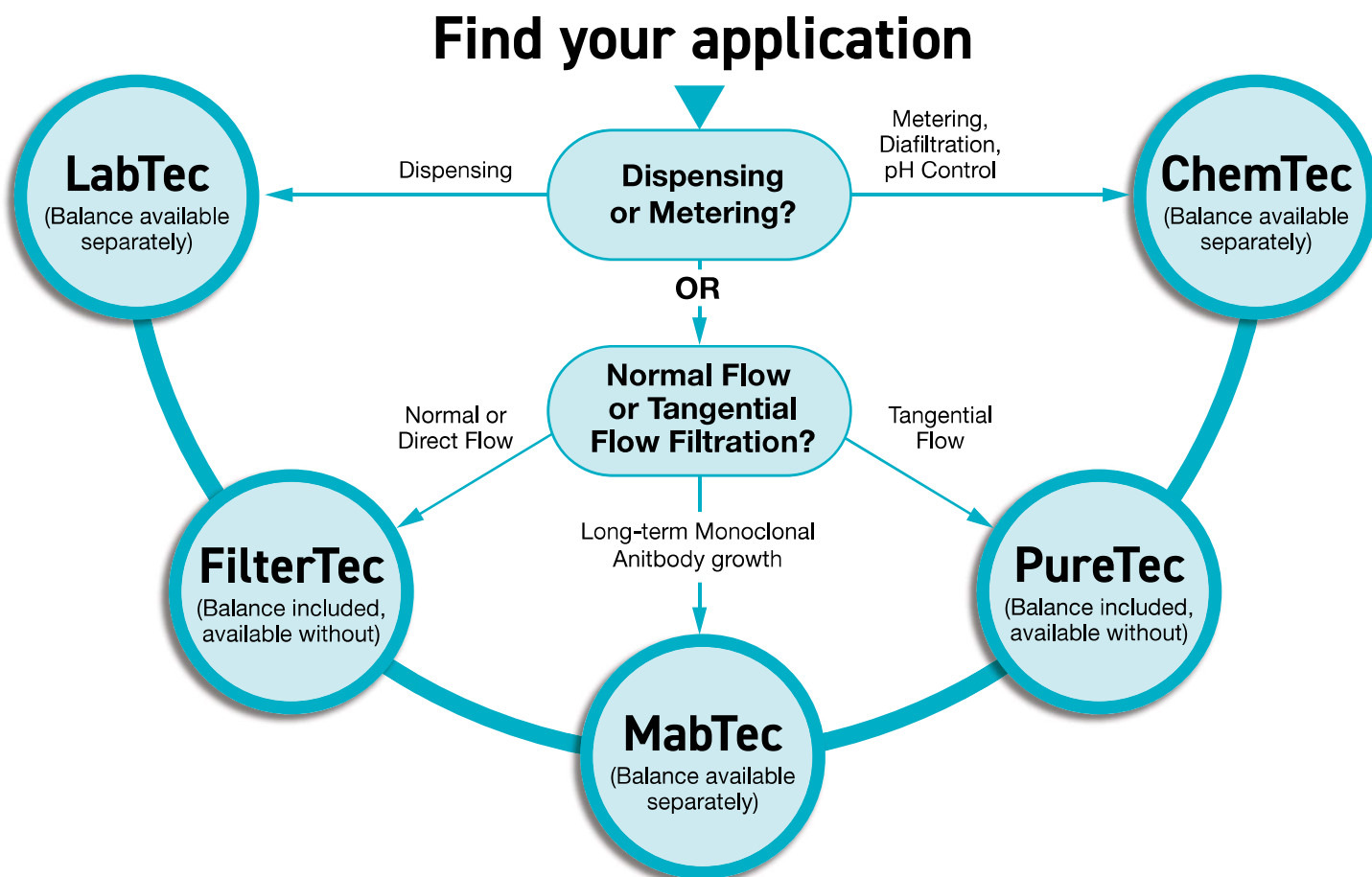

Motor RPM/Pump Head Choices

Pump Head Model		TANDEM 1081						TANDEM 1082		
Approved Tubing Size		13	14	16	25	17	18	15	24	35
Silicone Part #		400-113	400-114	400-116	400-125	400-117	400-118	400-115	400-124	400-135
PharMed Part #		400-313	400-314	400-316	400-325	400-317	400-318	400-315	400-324	400-335
Your Motor	Pump Rate Range (Nominal values, +/-5%)	ml/min	ml/min	ml/min	ml/min	ml/min	ml/min	ml/min	ml/min	ml/min
☐ CP-8	8 RPM	0.03 - 0.45	0.1 - 1.6	0.4 - 6.4	0.9 - 12.6	1.1 - 18.3	1.7 - 24.3	0.5 - 13	0.6 - 20	0.8 - 32
☐ CP-120	160 RPM	0.5 - 10	1.7 - 35	6.3 - 129	12.5 - 283	18.5 - 405	24.7 - 554	9.6 - 240	14 - 412	16 - 650
☐ CP-200	600 RPM	2 - 34	8.6 - 132	29 - 533	49 - 974	70 - 1048	103 - 1515	59 - 993	85 - 1348	111 - 2258



For additional support:
bioscienceNA.ts@parker.com | 877.784.2234 | parker.com/bioscience