


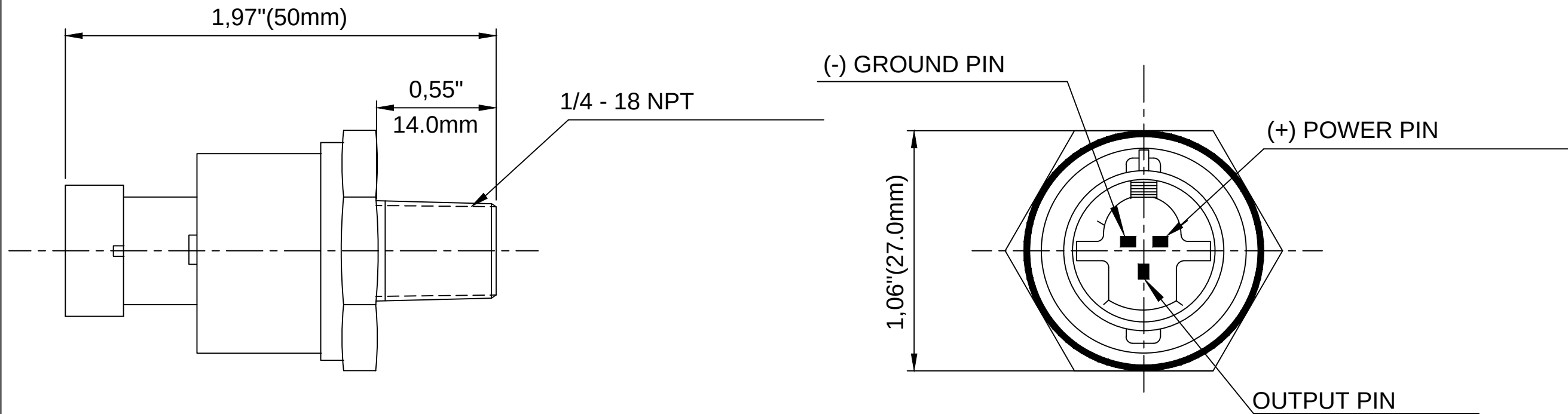

- NOTES:
- 1. SUPPLY AND OUTPUT SHARE COMMON GROUND.
 - 2. LOAD MUST BE EQUAL OR GREATER THAN 3000 Ω
 - 3. OUTPUT CAN BE SHORTED TO GROUND.
DO NOT SHORT TO THE POSITIVE SUPPLY VOLTAGE.
 - 4. MOUNTING DIMENSIONS FOR REFERENCE ONLY

LEADWIRE COLOR CODE:
RED-SUPPLY VOLTAGE(+)
BLACK-GROUND(-)
GREEN OR WHITE-OUTPUT

SPECIFICATIONS

PART#: 9520001 (0-100psi)
9520002 (0-500psi)
9520004 (0-200psi)

SUPPLY VOLTAGE: 5VDC
SUPPLY CURRENT: 10mA MAX
OUTPUT SOURCE CURRENT: 0.5mA MAX

TEMPERATURE:(OPERATING AND STORAGE): -55 TO 125 °C
(-67 TO 257°F)

--	----	07
--	----	06
--	----	05
--	----	04
--	----	03
--	----	02
2014-12-01	Update Logo Adress	01
DATE	DESCRIPTION	REV.

SYSTEM :
REFRIGERATION

AUTOMATISATION / CONTROL :



Micro Thermo Technologies™
12855 Rue Brault, Mirabel
Quebec, Canada J7J 0C4
Tel: (450) 668-3033
Fax: (450)668-2695

TITLE:
PRESSURE TRANSDUCER

PART#:
952-000X

Drawn By : G.Q.	Designed By : L.M.	Approved By : A.H.	Revision : 01
Scale : N.T.S	Date : 2004-08-26	File Name : S-003 PROBE 952-000X	