


F5OHAO

Straight Thread Union
SAE-ORB / SAE-ORB

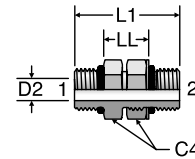

TUBE FITTING PART #	HOSE FITTING PART #	END SIZE		C4 HEX (in.)	D2 DRILL	L1 (in.)	LL AFTER ASSY (in.)	Dynamic Pressure (x 1,000 PSI)		
		1 UN/UNF-2A	2 UN/UNF-2A					-S	-SS	-B
4 F5OHAO	0505-4-4	7/16 - 20	7/16 - 20	9/16	0.203	1.27	0.52	6.0	6.0	3.3
6 F5OHAO	0505-6-6	9/16 - 18	9/16 - 18	11/16	0.297	1.41	0.59	6.0	6.0	3.3
8 F5OHAO	0505-8-8	3/4 - 16	3/4 - 16	7/8	0.422	1.64	0.71	6.0	6.0	3.3
10 F5OHAO	0505-10-10	7/8 - 14	7/8 - 14	1	0.484	1.81	0.75	5.0	5.0	3.3
12 F5OHAO	0505-12-12	1 1/16 - 12	1 1/16 - 12	1 1/4	0.656	2.13	0.89	5.0	5.0	3.3
16 F5OHAO	0505-16-16	1 5/16 - 12	1 5/16 - 12	1 1/2	0.875	2.44	1.20	4.0	4.0	2.6
20 F5OHAO	0505-20-20	1 5/8 - 12	1 5/8 - 12	1 7/8	1.078	2.44	1.20	4.0	4.0	2.6
24 F5OHAO	0505-24-24	1 7/8 - 12	1 7/8 - 12	2 1/8	1.344	2.44	1.20	3.0	3.0	1.9
32 F5OHAO	0505-32-32	2 1/2 - 12	2 1/2 - 12	2 3/4	1.813	2.44	1.20	2.0	2.0	1.3

Dimensions and pressures for reference only, subject to change.

