


## KDS Soft sealing ring for banjo fittings WH/TH from steel

for small and wide spot faces of ports

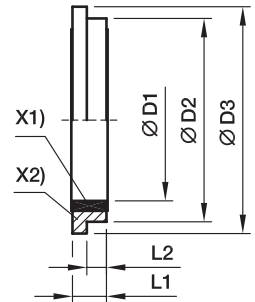

X1) NBR sealing  
X2) Supporting-ring (Steel)

For WH and TH	For thread		D1	D2	D3	L1	L2	Weight g/1 piece	Order code Steel/NBR	Order code Steel/FKM
06LM/LRKDS	M10×1	G 1/8 A	10.3	14.9	16.0	2.5	1.1	2	<b>KDS10A3CX</b>	<b>KDS10VITA3CX</b>
06SM/08LMKDS	M12×1.5		12.3	17.0	18.0	3.0	1.6	2	<b>KDS12A3CX</b>	<b>KDS12VITA3CX</b>
06SRKDS	M14×1.5	G 1/4 A	14.3	18.9	20.0	3.0	1.6	2	<b>KDS14A3CX</b>	<b>KDS14VITA3CX</b>
08LR/SM/SRKDS	M14×1.5	G 1/4 A	14.3	18.9	20.0	3.0	1.6	2	<b>KDS14A3CX</b>	<b>KDS14VITA3CX</b>
10LM/LRKDS	M14×1.5	G 1/4 A	14.3	18.9	20.0	3.0	1.6	2	<b>KDS14A3CX</b>	<b>KDS14VITA3CX</b>
10SM/SRKDS	M16×1.5	G 3/8 A	17.0	21.9	24.0	3.0	2.1	3	<b>KDS16A3CX</b>	<b>KDS16VITA3CX</b>
12LM/LR/SRKDS	M16×1.5	G 3/8 A	17.0	21.9	24.0	3.0	2.1	3	<b>KDS16A3CX</b>	<b>KDS16VITA3CX</b>
12SM/15LMKDS	M18×1.5		18.3	23.9	23.9	3.0		4	<b>KDS18A3CX</b>	<b>KDS18VITA3CX</b>
15LRKDS	M22×1.5	G 1/2 A	22.3	26.9	30.0	4.5	2.6	7	<b>KDS22A3CX</b>	<b>KDS22VITA3CX</b>
16SM/SRKDS	M22×1.5	G 1/2 A	22.3	26.9	30.0	4.5	2.6	7	<b>KDS22A3CX</b>	<b>KDS22VITA3CX</b>
18LM/LRKDS	M22×1.5	G 1/2 A	22.3	26.9	30.0	4.5	2.6	7	<b>KDS22A3CX</b>	<b>KDS22VITA3CX</b>
22LMKDS	M26×1.5		26.3	31.9	35.0	3.5	2.6	7	<b>KDS26A3CX</b>	<b>KDS26VITA3CX</b>
20SM/SRKDS	M27×2	G 3/4 A	27.3	32.9	38.0	3.5	2.6	8	<b>KDS27A3CX</b>	<b>KDS27VITA3CX</b>
22LRKDS	M27×2	G 3/4 A	27.3	32.9	38.0	3.5	2.6	8	<b>KDS27A3CX</b>	<b>KDS27VITA3CX</b>
25SM/SRKDS	M33×2	G 1 A	33.6	39.9	42.0	3.5	2.6	10	<b>KDS33A3CX</b>	<b>KDS33VITA3CX</b>
28LM/LRKDS	M33×2	G 1 A	33.6	39.9	42.0	3.5	2.6	10	<b>KDS33A3CX</b>	<b>KDS33VITA3CX</b>
30SM/SRKDS	M42×2	G 1 1/4 A	42.4	49.9	49.9	3.5		12	<b>KDS42A3CX</b>	<b>KDS42VITA3CX</b>
35LM/LRKDS	M42×2	G 1 1/4 A	42.4	49.9	49.9	3.5		12	<b>KDS42A3CX</b>	<b>KDS42VITA3CX</b>
38SM/SRKDS	M48×2	G 1 1/2 A	48.4	55.9	60.0	3.5	2.6	16	<b>KDS48A3CX</b>	<b>KDS48VITA3CX</b>
42LM/LRKDS	M48×2	G 1 1/2 A	48.4	55.9	60.0	3.5	2.6	16	<b>KDS48A3CX</b>	<b>KDS48VITA3CX</b>